


6" x 6" Translucent, IR Material Window

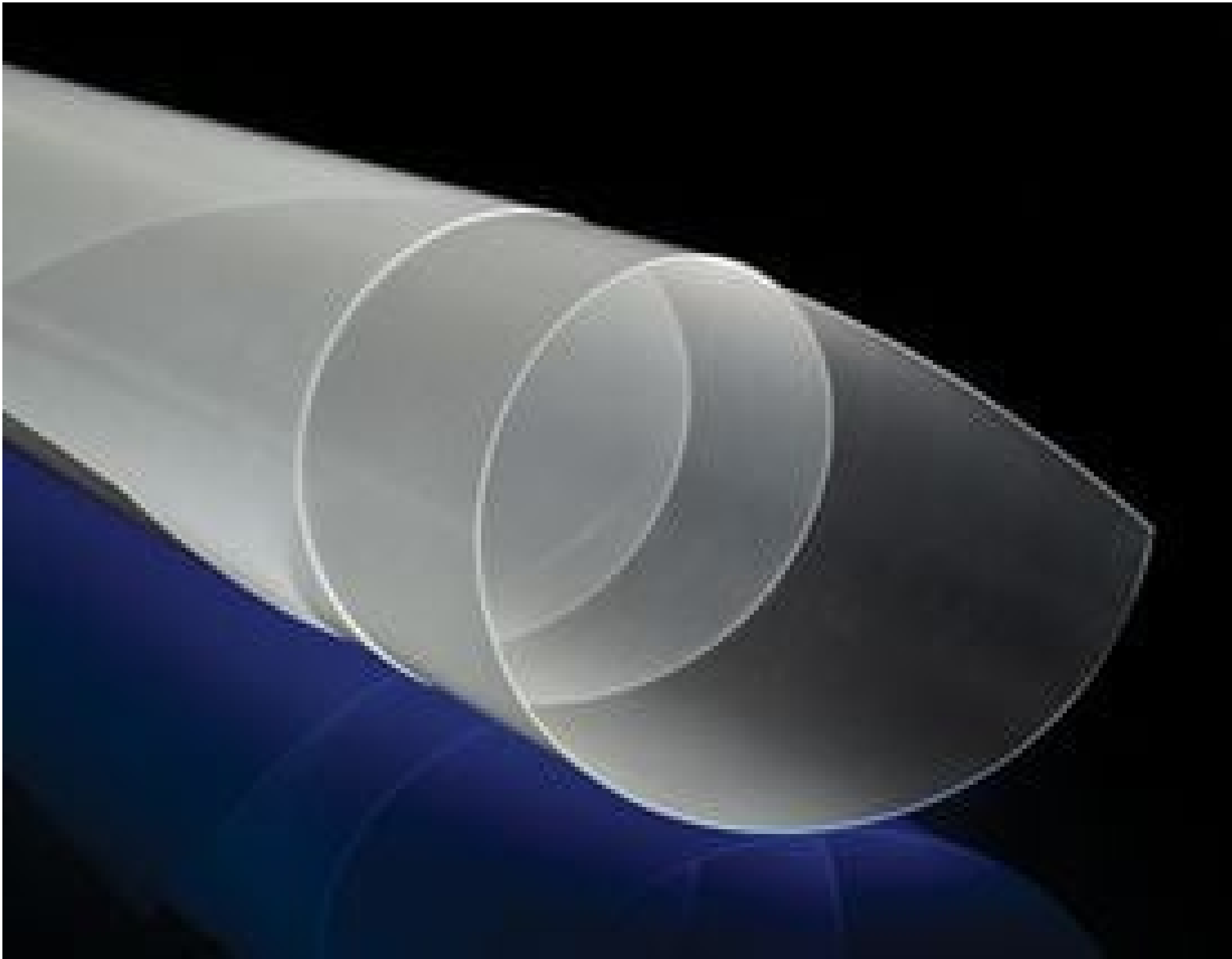

Stock **#32-806** ☐ In Stock

-

1

+

€28,00

ADD TO CART

Qty 1-5
€28,00
Qty 6+
€25,25
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
152.40 x 152.40

Dimensions (inches):
6.00 x 6.00

Thickness (mm):
0.38

Thickness (inches):

0.015
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 11 - 13
Color: Translucent
Flexural Modulus (psi): (100-260) x 10 ³
Index of Refraction n_d: Visible (Sodium D Line): 1.52 8-14µm: 1.53 15µm+: 1.48
Operating Temperature (°C): 100 (Max)
Shore Hardness: D60-70
Substrate: ☐ Polymer Film
Type: Protective Window
Wavelength Range (nm): 8000 - 14000
Young's Modulus (GPa): 0.40 - 1.24

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View