


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

TECHSPEC® 75 X 75mm Stabilized Wire Grid Polarizing Film

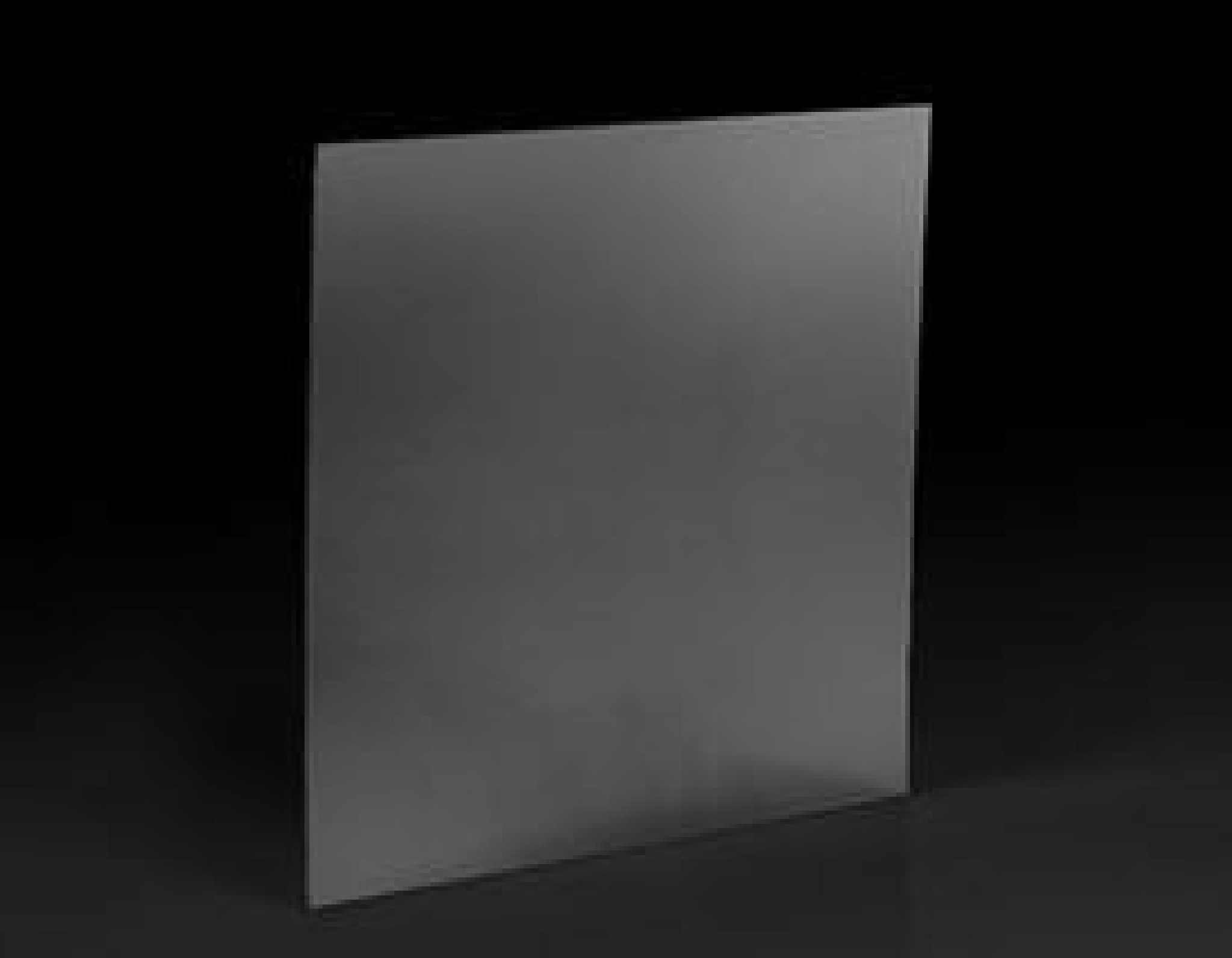

TECHSPEC® Wre Grid Polarizing Film

Stock #20-238 [CONTACT US](#)



1



€272,00

ADD TO CART

Qty 1-10

€272,00

Qty 11+

€232,00

Volume Pricing

[Request Quote](#)

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle of Incidence (°):
0 - 45

Extinction Ratio:
>1415:1 @ 0° AOI, 550nm

Substrate: ☐

Aluminium Wires on COP
Operating Temperature (°C): 60 Max @ 90% RH 105 in dry conditions
Dimensions (mm): 75 x 75
Thickness (mm): 0.19
Thickness Tolerance (mm): ±0.030
Transmission (%): 84.9 (typical @ 550 nm)
Type: Linear Polarizer
Dimensional Tolerance (mm): +0/-0.3
Construction: Wire Grid
Wavelength Range (nm): 400 - 1200
Axis Orientation: 0° ± 1.5°, marked by Notch

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant