


TECHSPEC® 75 x 75mm Protected Silver, λ/20 Mirror

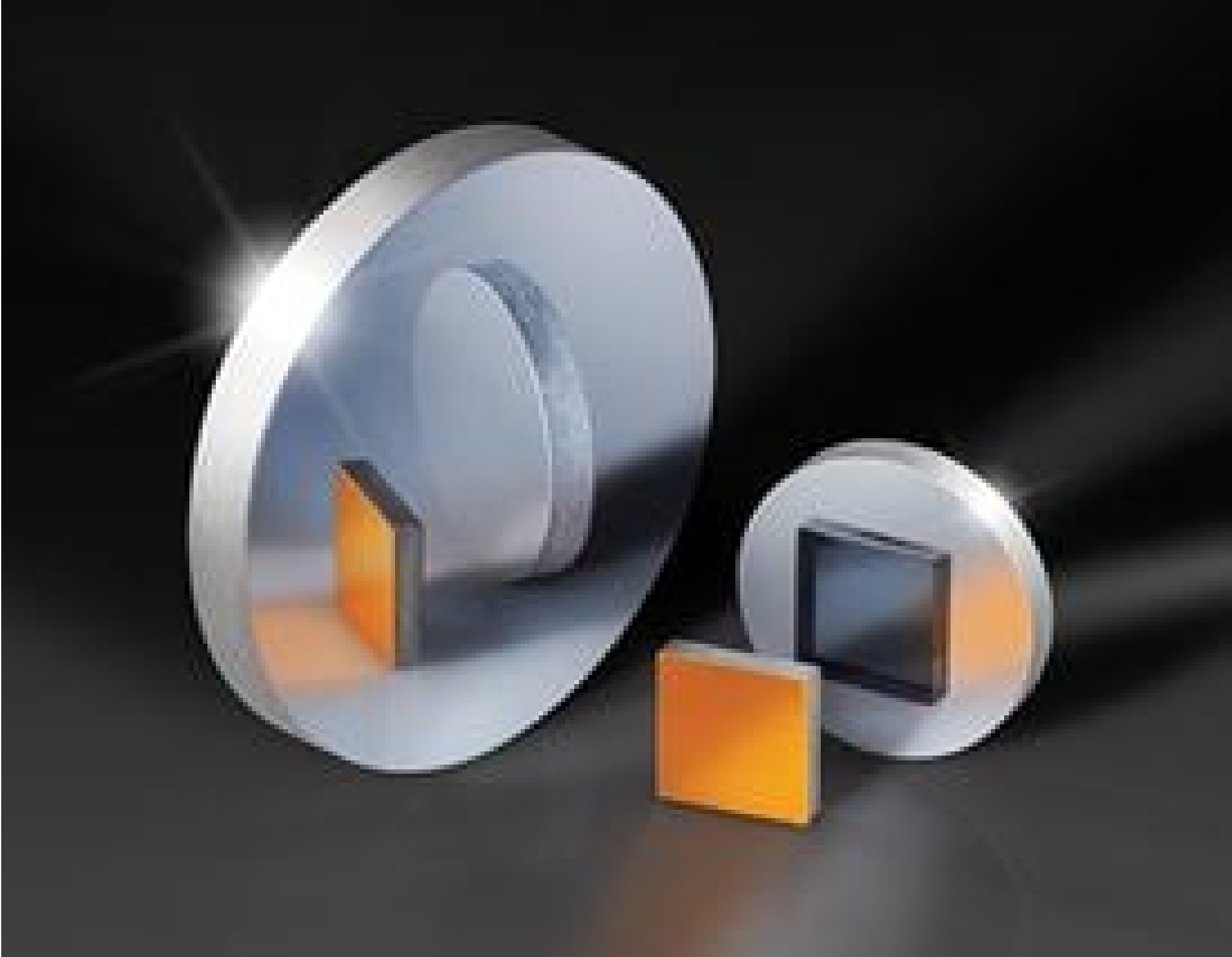

Stock **#34-401** [CONTACT US](#)

⊖ 1 ⊕ **€599,00**

ADD TO CART

Qty 1-5
€599,00

Qty 6+
€479,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/20 (flatness pre-coating)

Substrate: [Fused Silica](#) (Corning 7980)

Back Surface:
Commercial Polish

Surface Quality: 20-10
Dimensions (mm): 75.0 x 75.0 +0.00/-0.20
Coating Specification: R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 7.50
Type: Flat Mirror
Wavelength Range (nm): 450 - 10000
Length (mm): 75.00
Width (mm): 75.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant