


8" x 10", Uncoated Plastic Acrylic Window

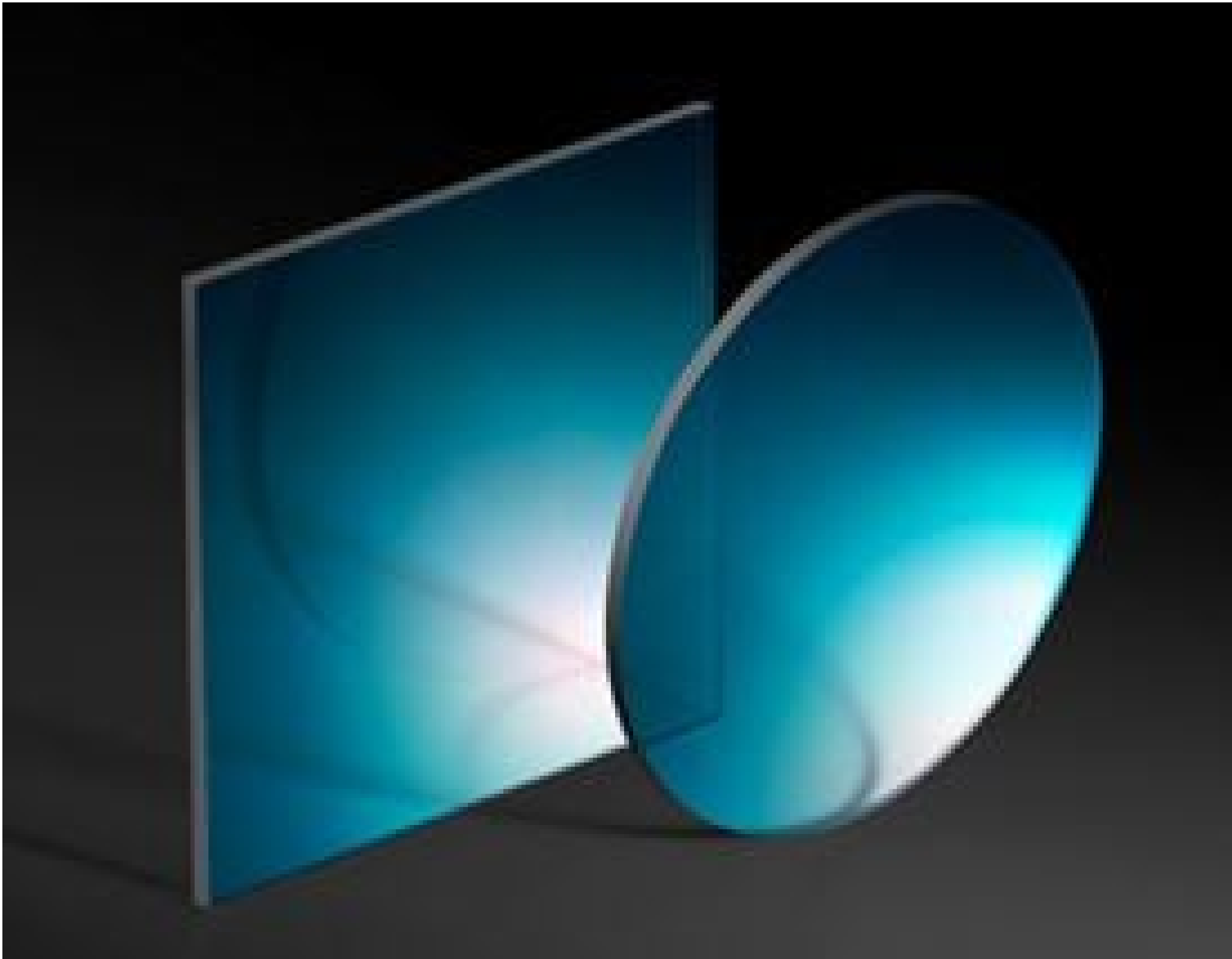

Stock **#19-640** 3-4 DAYS

- 1 + **€85,00**

ADD TO CART

Qty 1-5
€85,00

Qty 6+
€68,00

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Abbe Number (v_d):
58

Bevel:
Protective as needed

Clear Aperture CA (mm):
182.88 x 228.60

Dimensions (mm):

203.2 x 254.0 ±0.254
Dimensions (inches): 8.00 x 10.00 ±0.010
Thickness (mm): 1.52 ±0.1
Thickness (inches): 0.06
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 60
Edges: Smooth, Machined
Index of Refraction n_d: 1.49
Substrate: PMMA
Type: Protective Window
Wavelength Range (nm): 400 - 1600
Length (mm): 202.30
Width (mm): 254.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View