


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 8" Dia. Protected Aluminum, N10 Flat Fused Silica

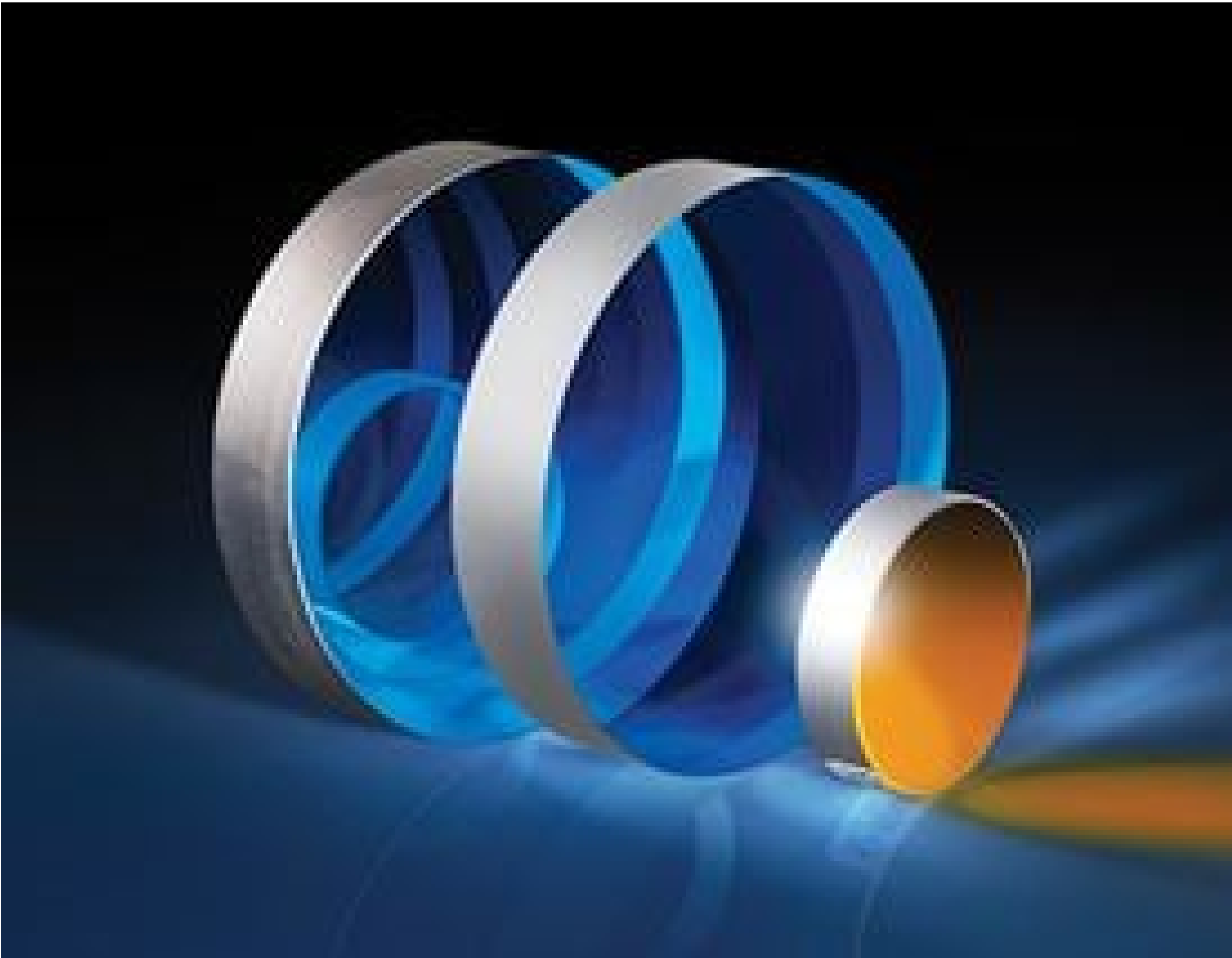

Stock #31-390-522 CONTACT US

1 €3.938,00

ADD TO CART

Qty 1-2
€3.938,00

Qty 3+
€3.544,00

Volume Pricing
[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
N10 (measured before coating)

Back Surface:
Commercial Polish

Surface Quality: 60-40
Diameter (mm): 203.20 +0.0/-1.0
Substrate: Fused Silica (Coming 7980)
Coating Specification: R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm
Coating: Protected Aluminum (400-2000nm)
Coating Type: Metal
Clear Aperture CA (mm): 182.88
Note: Flatness is specified as Peak to Valley
Thickness (mm): 38.10 ±2.5
Thickness Tolerance (mm): ±2.5
Type: Flat Mirror
Wavelength Range (µm): 0.4 - 2
Wavelength Range (nm): 400 - 2000
Damage Threshold, Reference: View 0.3 J/cm ² @ 532nm & 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant