


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 8" Dia. Protected Silver, N/10 Flat Fused Silica

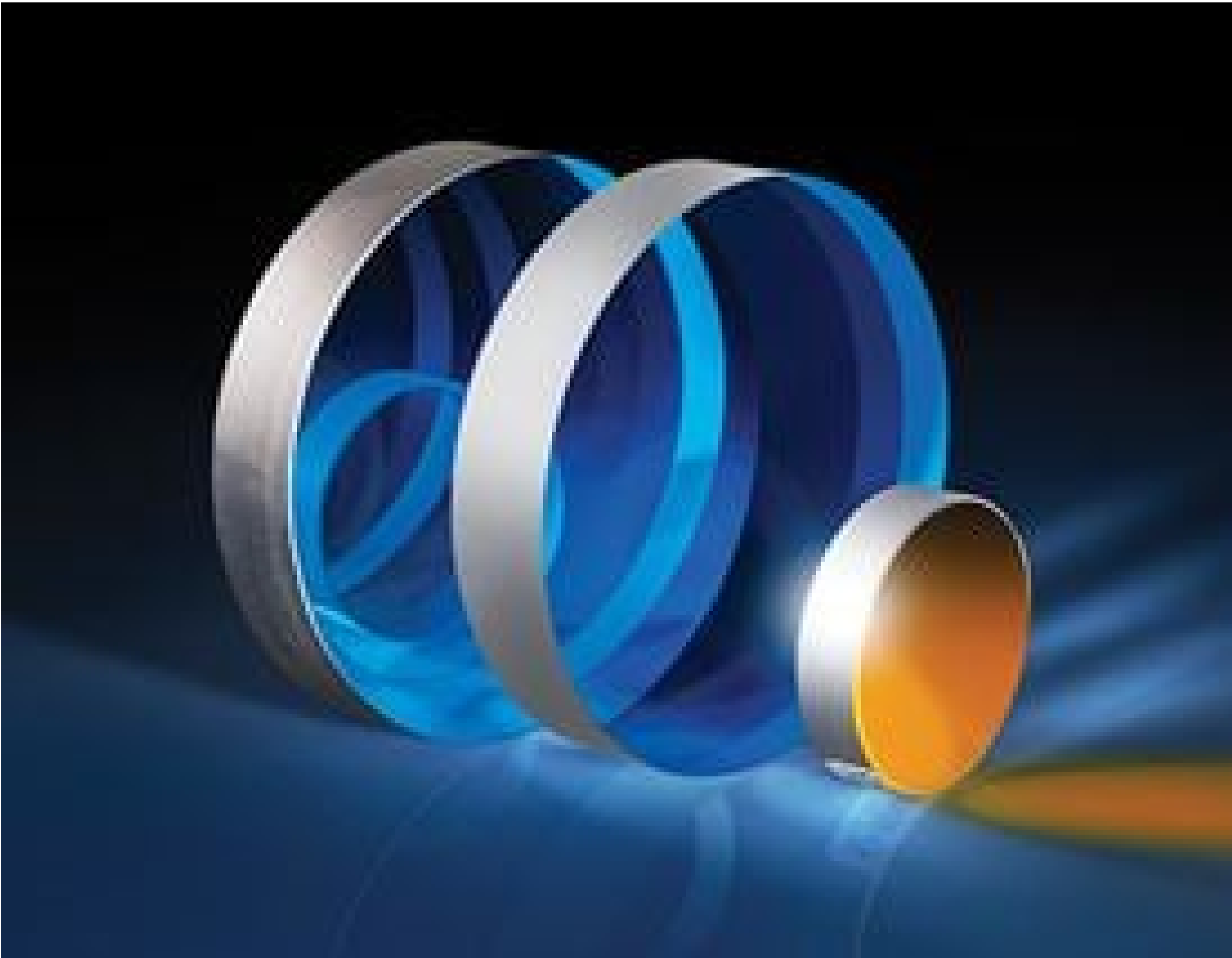

Stock #31-390-577 3-4 DAYS

1 €4.063,00

ADD TO CART

Qty 1-2

€4.063,00

Qty 3+

€3.657,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
N/10 (measured before coating)

Back Surface:
Commercial Polish

Surface Quality: 60-40
Diameter (mm): 203.20 +0.0/-1.0
Substrate: ☐ Fused Silica (Corning 7980)
Coating Specification: R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Clear Aperture CA (mm): 182.88
Note: Flatness is specified as Peak to Valley
Thickness (mm): 38.10 ±2.5
Thickness Tolerance (mm): ±2.5
Type: Flat Mirror
Wavelength Range (µm): 0.45 - 10
Wavelength Range (nm): 450 - 10000
Damage Threshold, Reference: ☐ 0.5 J/cm ² @ 532nm & 1064nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant