


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

8" X 10", Optical Cast Plastic IR Longpass Filter

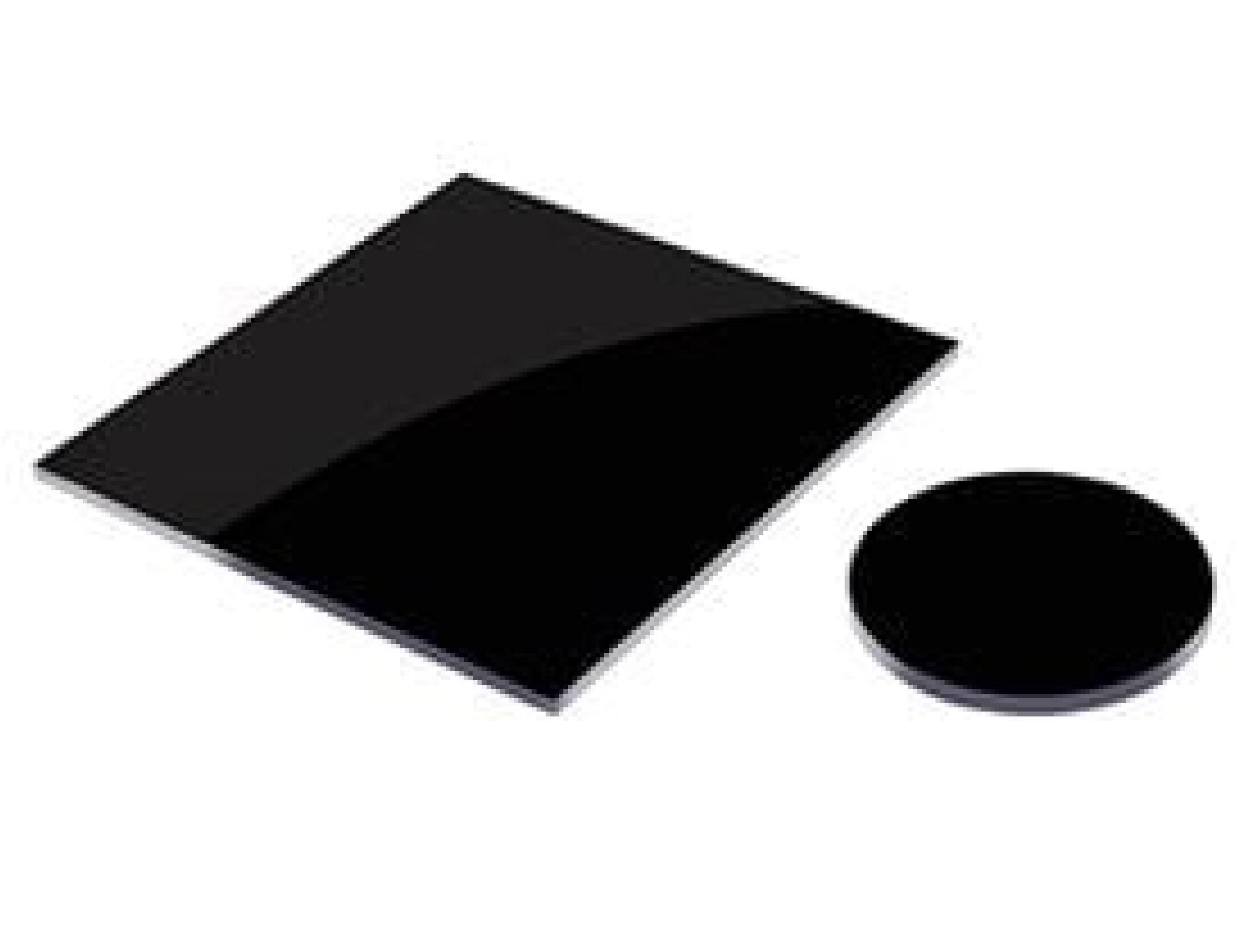

Stock **#46-621** 3-4 DAYS



1



€147,00

ADD TO CART

Qty 1-49

€147,00

Qty 50+

€132,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
203.2 x 254.0

Density (g/cm³):
1.320 at 20°C

Substrate: ☐
Thermoset ADC (CR-39®)

Length (mm):

254.00
Operating Temperature (°C): 100 Continuous, 130 One Hour Max
Coating: Uncoated
Color: Black
Index of Refraction n_d: 1.501 @ 20°C
Dimensions (inches): 8 x 10
Thickness (mm): 1.50 Nominal
Transmission (%): >90 (typical)
Type: Longpass Filter
Width (mm): 203.20
Dimensional Tolerance (mm): ±0.3
Abbe Number (v_d): 57.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View