


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

92 Grooves/mm, 12.7 mm Sq, Transmission Grating Beamsplitter

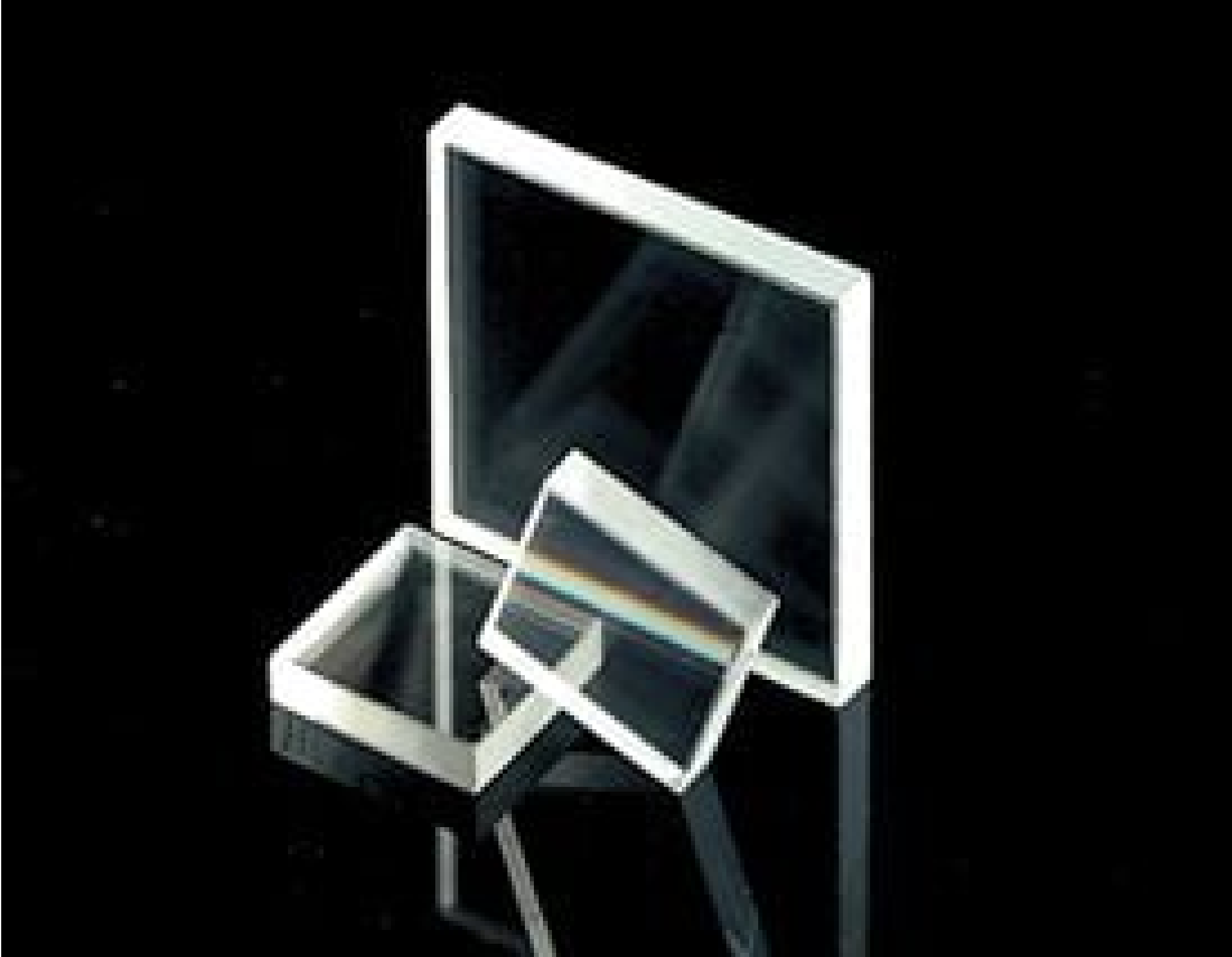

Stock #46-071 3-4 DAYS

- 1 + €130,00

ADD TO CART

Qty 1-10

€130,00

Qty 11+

€117,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):  
92

Design Wavelength DWL (nm):  
632.8

Dimensions (mm):  
12.7 x 12.7 ±0.5

|                                                                    |
|--------------------------------------------------------------------|
| <b>Construction:</b><br>Blazed Grating                             |
| <b>Length (mm):</b><br>12.70                                       |
| <b>Substrate:</b> <input type="checkbox"/><br><a href="#">E270</a> |
| <b>Thickness (mm):</b><br>3.00 ±0.5                                |
| <b>Type:</b><br>Transmission Diffraction Grating                   |
| <b>Width (mm):</b><br>12.70                                        |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 219:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |

---