

4.0 - 36.0mm Optic Dia., Self-Centering Jaw Clamp



Self-Centering Jaw Clamps

Stock **#16-077** **5 In Stock**

-

1

+

€157⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-4	€157,00 each
Qty 5+	€138,40 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

Type: Fixed

Type of Optics:

Circular

Physical & Mechanical Properties

74	Height (mm):
58	Outer Diameter (mm):
0.09	Weight (lbs):
Black Anodized Aluminum	Construction:

Threading & Mounting

4.0 - 36.0	Size of Compatible Optics (mm):
M4 x0.7, 8-32	Compatible Post:

Regulatory Compliance


Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

PRODUCT DETAILS

- Two Mount Sizes Available, for 4mm-36mm and 5mm-100mm Dia. Optics
- Optical Centerline Remains Constant Regardless of Optical Diameter
- Mounts Feature Both Metric and English Tapped Mounting Holes

Self-Centering Jaw Clamps are ideal for easily interchanging optics of different diameters in a system while maintaining a constant optical centerline of the system. Mounts are available for either mounting 4mm to 36mm diameter optics ([#16-077](#)) or 5mm to 100mm diameter optics ([#16-078](#)). The small jaw clamp features both M4 x0.7 and 8-32 tapped mounting holes, while the large jaw clamp features both M6 x 1.0 and ¼"-20 tapped mounting holes. The stainless-steel tipped jaws feature a v-groove to help vertical alignment of thinner optics. Self-Centering Jaw Clamps are directly mountable to [TECHSPEC® Stainless Steel Mounting Posts](#) and [Pedestal Posts](#).

TECHNICAL INFORMATION

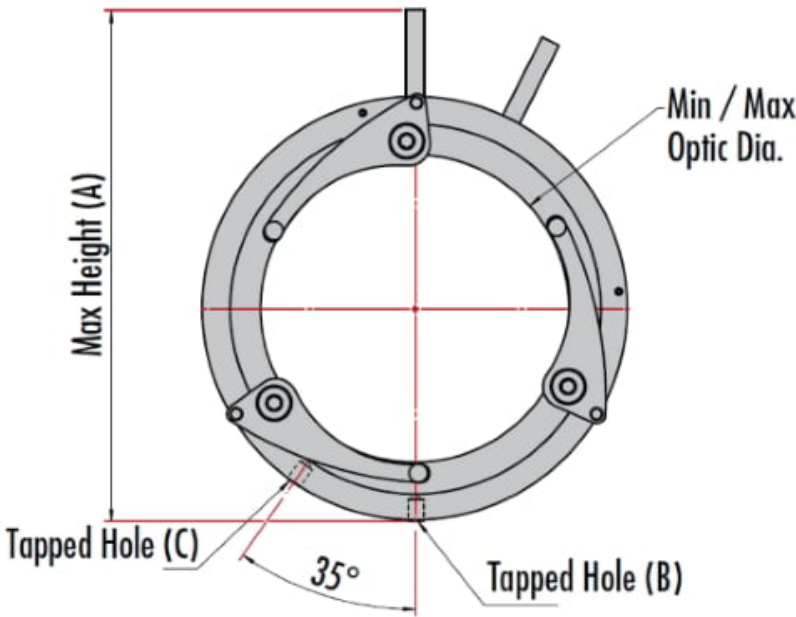

Outer Diameter (mm)	Min. Optic Diameter (mm)	Max. Optic Diameter (mm)	A (mm)	B	C	Stock No.
58	4	36	74	#8-32	M4 x0.7	#16-077
138	5	100	166	¼-20	M6 x 1.0	#16-078