

Adapter Plate for #55-028



#55-037

#55-037

Stock **#55-037** **20+ In Stock**

⊖ 1 ⊕ €37⁷⁵

ADD TO CART

Volume Pricing

Qty 1-9	€37,75 each
Qty 10+	€33,90 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Adapter Brackets & Plates **Type:**

Physical & Mechanical Properties

1.57 **Length (inches):**

40.00 **Length (mm):**

40 x 40 x 5

Dimensions (mm):

Threading & Mounting

Mounting Threads:

(4) M2 x 0.4, (4) M3 x 0.5, (1) 1/4-20

Regulatory Compliance

RoHS 2015:

Compliant

Certificate of Conformance:

[View](#)

Reach 247:


Compliant

Product Details

- Precision Micrometer Drive and Manual Drive Options
- 360° Coarse Rotation
- Micrometer Drive Models Provide $\pm 5^\circ$ Fine Rotation
- Black Anodized Aluminum Construction

Metric Rotary Stages feature slide-fit guide system, enabling 360° course rotation. Micrometer drive models feature a precision metric micrometer and a switchable clamp mechanism to change between course and fine movements for precise $\pm 5^\circ$ angular adjustment at any position. The manual drive model provides a smooth manual adjustment with 360° coarse movement, 1° increments. Metric Rotary Stages feature a locking mechanism to fix the stage position. For breadboard mounting, use the [Metric Base Plates](#).

Technical Information

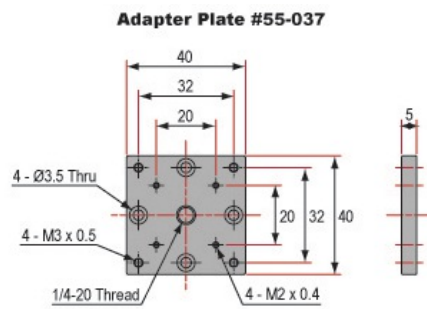

Units: mm