 


## Adapter Plate for #55-029



#55-038



Stock **#55-038** **5 In Stock**

- 1 + €38<sup>75</sup>

**ADD TO CART**

### Volume Pricing

Qty 1-9	€38,75 each
Qty 10+	€34,80 each
Need More?	<a href="#">Request Quote</a>

ⓘ Prices shown are exclusive of VAT/local taxes

### Product Downloads

### General

Adapter Brackets & Plates **Type:**

### Physical & Mechanical Properties

2.36 **Length (inches):**

Length (mm):  
60.00

Dimensions (mm):  
60 x 60 x 7

## Threading & Mounting

Mounting Threads:  
(4) M4 x 0.7, (4) M3 x 0.5, (4) M2 x 0.4, (1) 1/4-20

## Regulatory Compliance

RoHS 2015:  
[Compliant](#)

Certificate of Conformance:  
[View](#)


Reach 247:  
[Compliant](#)

## Product Details

- Precision Micrometer Drive and Manual Drive Options
- 360° Coarse Rotation
- Micrometer Drive Models Provide  $\pm 5^\circ$  Fine Rotation
- Black Anodized Aluminum Construction

Metric Rotary Stages feature slide-fit guide system, enabling 360° course rotation. Micrometer drive models feature a precision metric micrometer and a switchable clamp mechanism to change between course and fine movements for precise  $\pm 5^\circ$  angular adjustment at any position. The manual drive model provides a smooth manual adjustment with 360° coarse movement, 1° increments. Metric Rotary Stages feature a locking mechanism to fix the stage position. For breadboard mounting, use the [Metric Base Plates](#).

## Technical Information

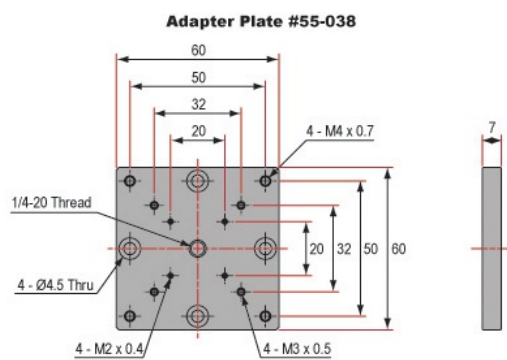

Units: mm