 



# Hoya B390 (UV-VIS) 50.8mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

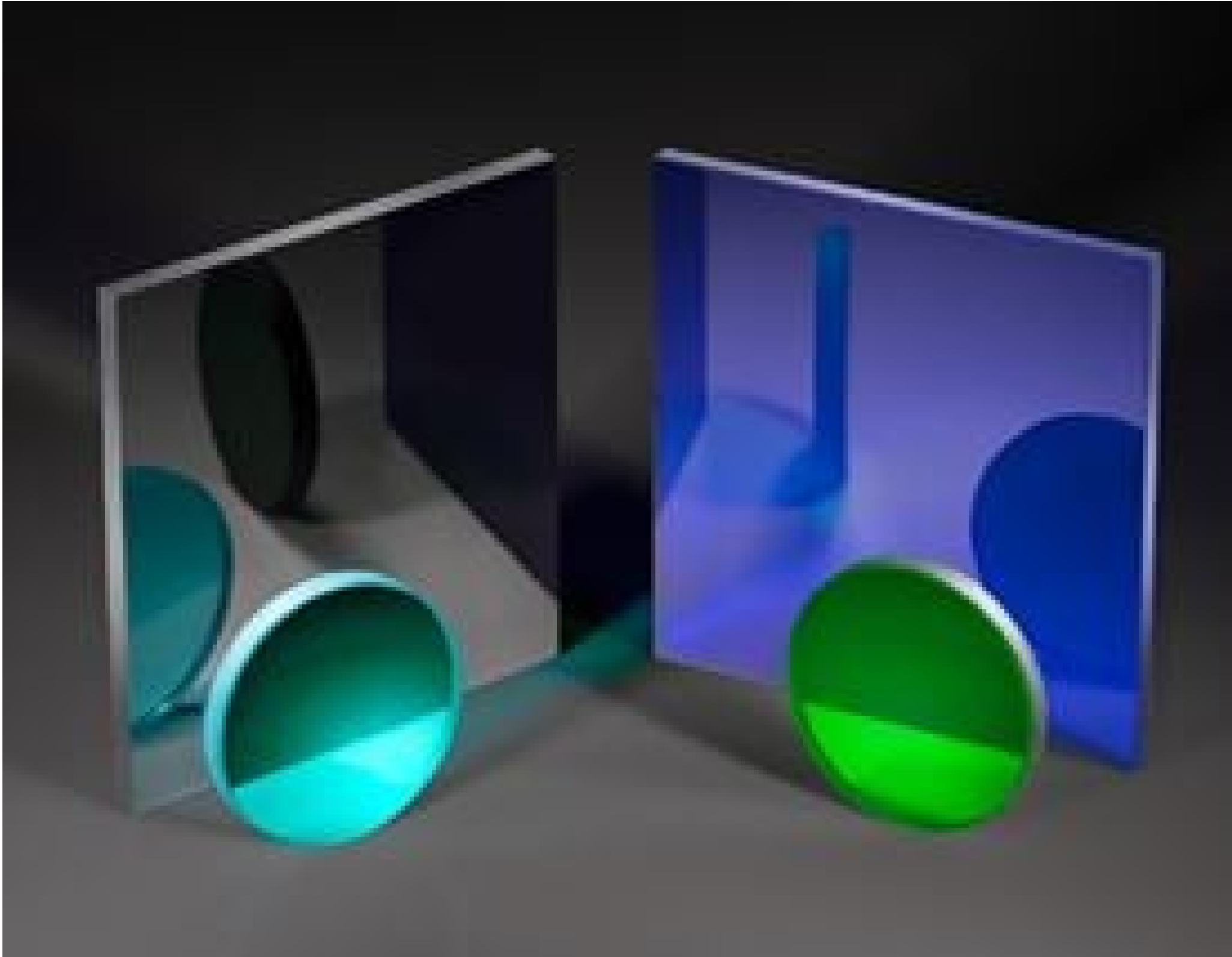

Stock **#48-640** 3-4 DAYS

- 1 +

€108,00

ADD TO CART

|          |
|----------|
| Qty 1-10 |
| €108,00  |

|         |
|---------|
| Qty 11+ |
| €96,00  |

|                               |
|-------------------------------|
| Volume Pricing                |
| <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):  
50.8 x 50.8

Center Wavelength CWL (nm):

|                                                      |
|------------------------------------------------------|
| 390.00                                               |
| Density (g/cm³):<br>2.57                             |
| Full Width-Half Max FWHM (nm):<br>125.00             |
| Glass/Filter Number:<br><a href="#">Hoya B390</a>    |
| Substrate: <input type="checkbox"/><br>Colored Glass |
| Length (mm):<br>50.80                                |
| Coating:<br>Uncoated                                 |
| Color:<br>Blue-Violet                                |
| Surface Quality:<br>60-40                            |
| Thickness (mm):<br>2.50                              |
| Thickness Tolerance (mm):<br>±0.2                    |
| Type:<br>Bandpass Filter                             |
| Wavelength:<br>UV-VIS                                |
| Width (mm):<br>50.80                                 |
| Parallelism (arcmin):<br>≤2                          |
| Dimensional Tolerance (mm):<br>+0/-0.25              |

### Regulatory Compliance

|                                                     |
|-----------------------------------------------------|
| RoHS 2015:<br><a href="#">Exempt</a>                |
| Reach 224:<br><a href="#">Compliant</a>             |
| Certificate of Conformance:<br><a href="#">View</a> |