

 

In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

Hoya B410 (UV-VIS) 12mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

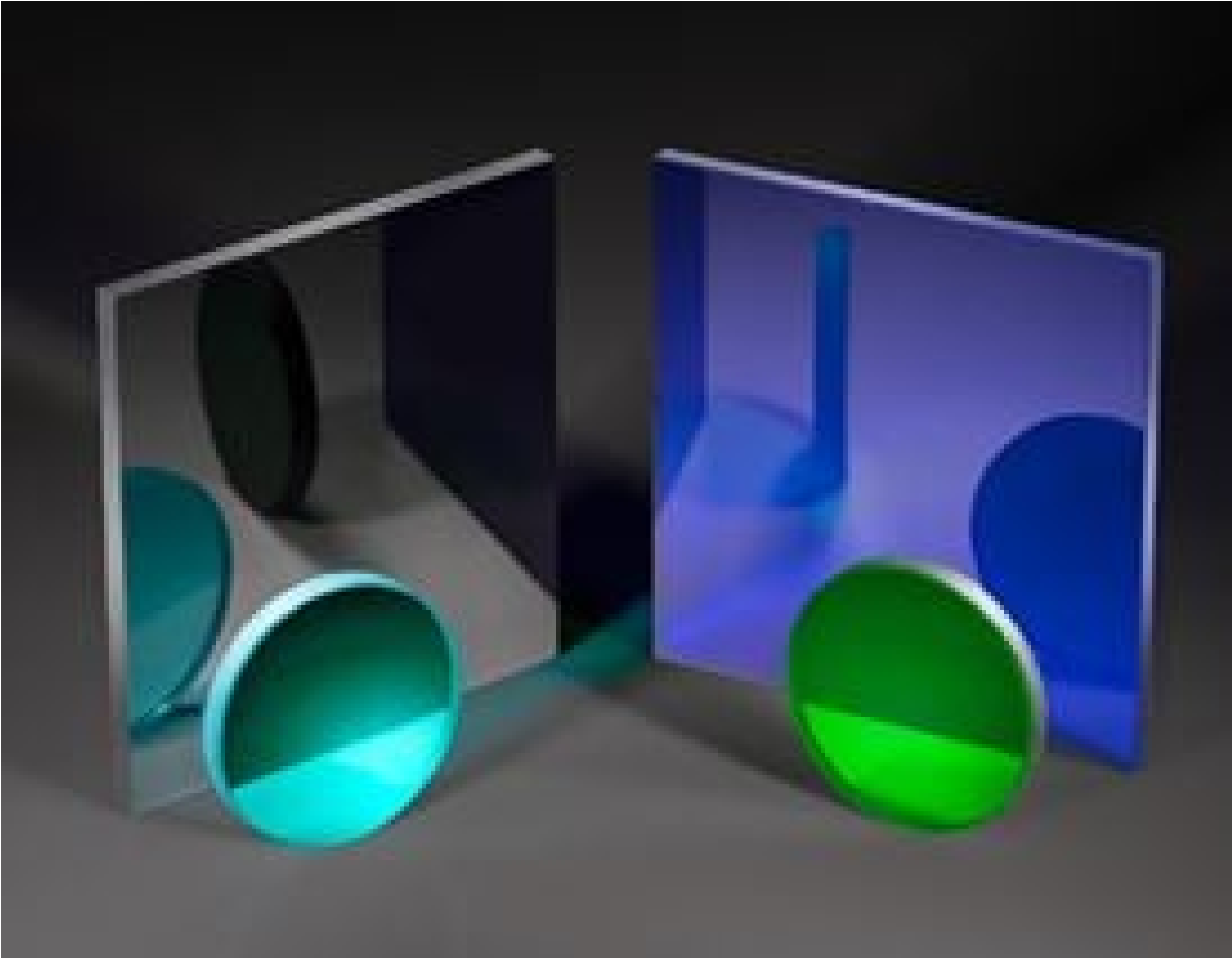

Stock #34-431 3-4 DAYS

1 €37,00

ADD TO CART

Qty 1-10

€37,00

Qty 11+

€33,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.00

Center Wavelength CWL (nm):

410.00
Density (g/cm³): 2.27
Full Width-Half Max FWHM (nm): 232.00
Glass/Filter Number: Hoya B410
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Blue
Surface Quality: 80-50
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV-VIS
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View