 



Hoya B460 (UV-VIS) 50.8mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

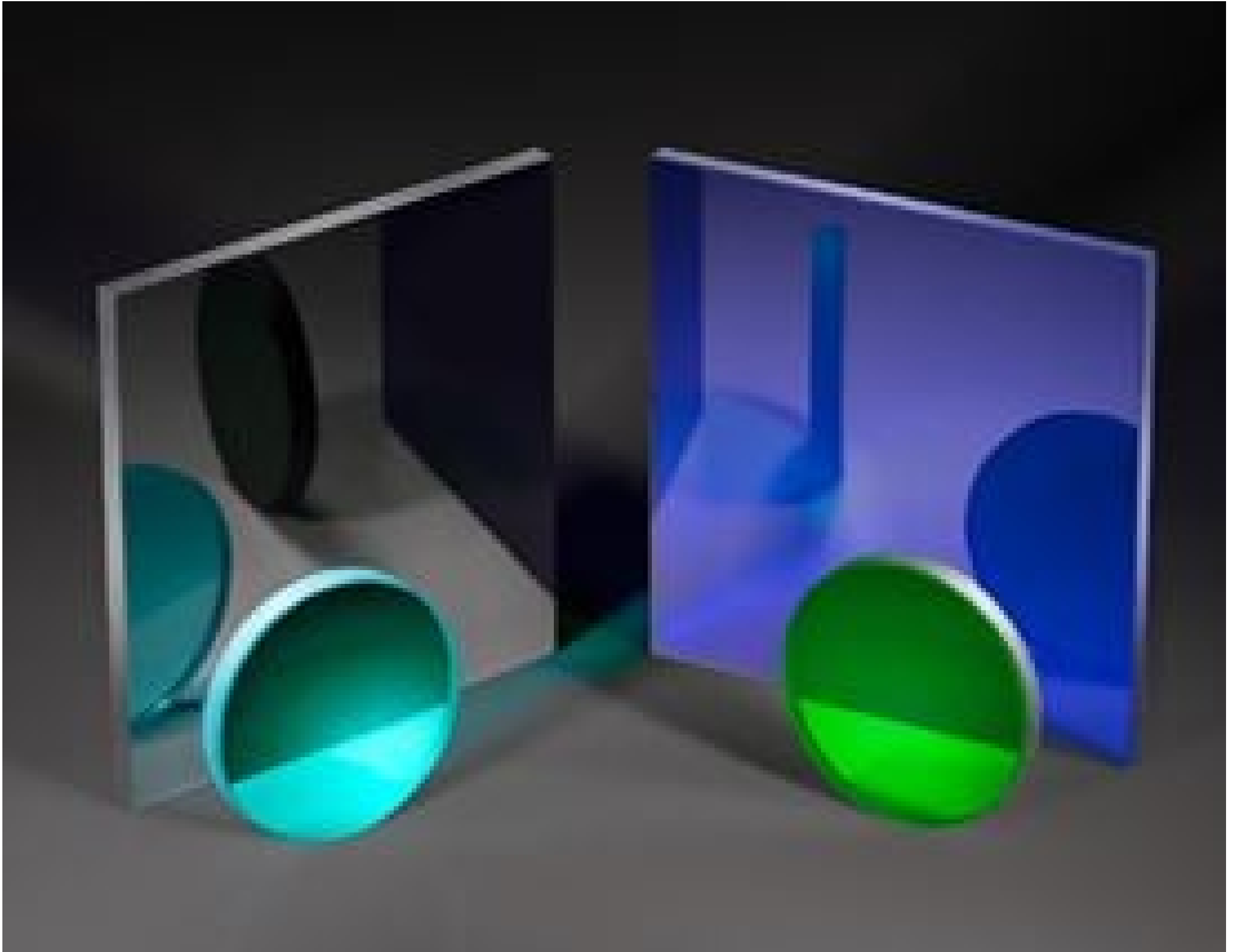

Stock #34-446 3-4 DAYS

⊖ 1 ⊕ **€108,00**

ADD TO CART

Qty 1-10

€108,00

Qty 11+

€96,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):
50.8 x 50.8

Center Wavelength CWL (nm):
460.00

Density (g/cm³):
2.60

Full Width-Half Max FWHM (nm):
200.00

Glass/Filter Number:
[Hoya B460](#)

Substrate:
Colored Glass

Length (mm):
50.80

Coating:
Uncoated

Color:
Blue-Green

Surface Quality:
80-50

Thickness (mm):
2.50

Thickness Tolerance (mm):
±0.2

Type:
Bandpass Filter

Wavelength:
UV-VIS

Width (mm):
50.80

Parallelism (arcmin):
≤2

Dimensional Tolerance (mm):
+0/-0.25

Regulatory Compliance

RoHS 2015:
[Exempt](#)

Reach 224:
[Compliant](#)

Certificate of Conformance:
[View](#)