

In order to provide more accurate inventory information, please select your shipping country.


Select Your Country/Region: European Union



SUBMIT

SCHOTT BG38, 25.4mm Dia., 3mm Thick, Colored Glass Bandpass Filter

See More by [SCHOTT Optical Components](#)

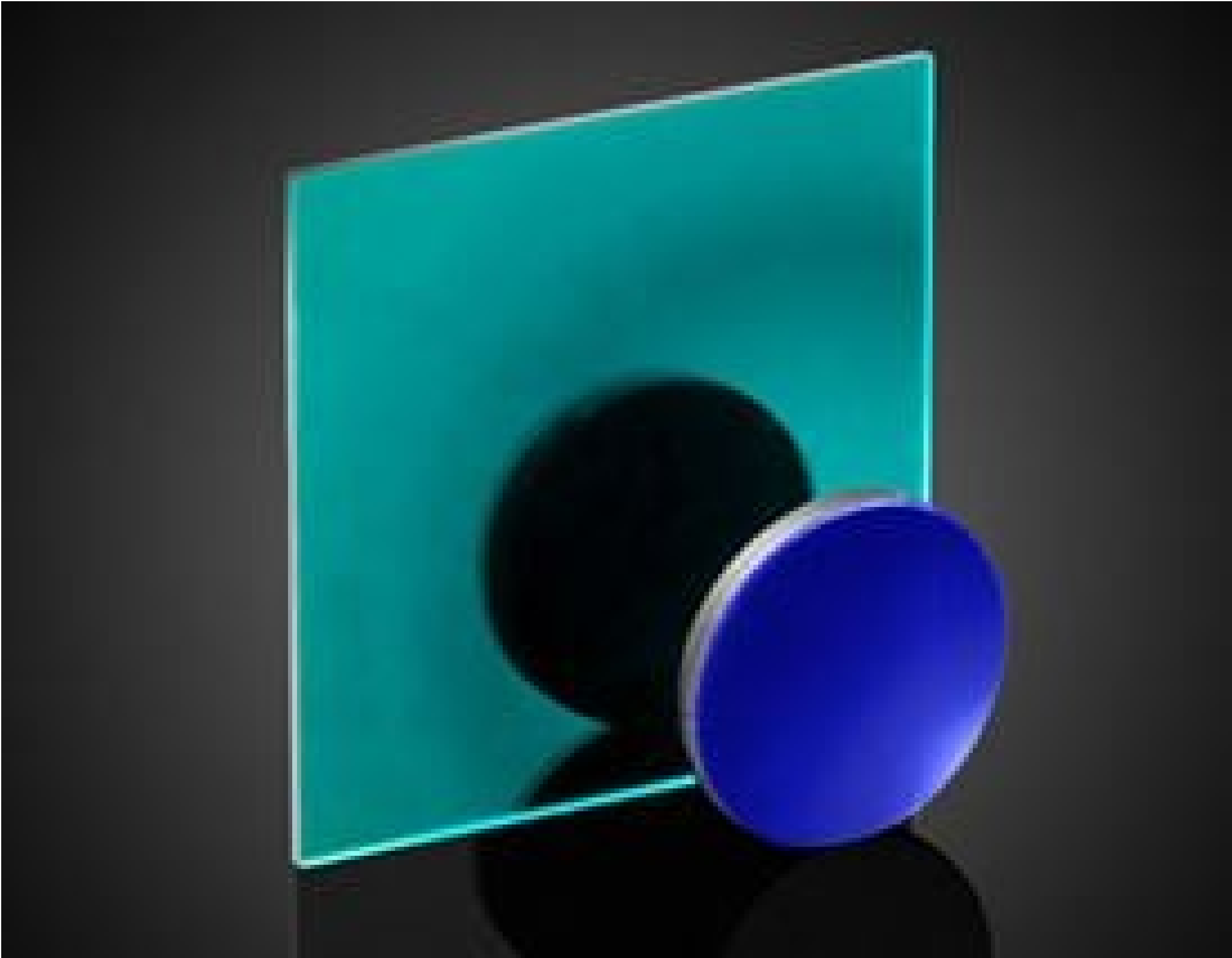

Stock **#46-433** [CONTACT US](#)



1



€47,00

ADD TO CART

Qty 1-10

€47,00

Qty 11+

€41,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Diameter (mm):
25.40

Center Wavelength CWL (nm):
470.00

Density (g/cm³): 2.62
Glass/Filter Number: SCHOTT BG38
Coating: Uncoated
Color: Blue-Green
Surface Quality: 80-50
Thickness (mm): 3.00 ±0.2
Type: Bandpass Filter
Wavelength: VIS
Note: Can also be used as a shortpass filter with a cut-off wavelength of 645nm
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View