 



Hoya B370 (UVVIS) 25.4mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [Hoya](#)

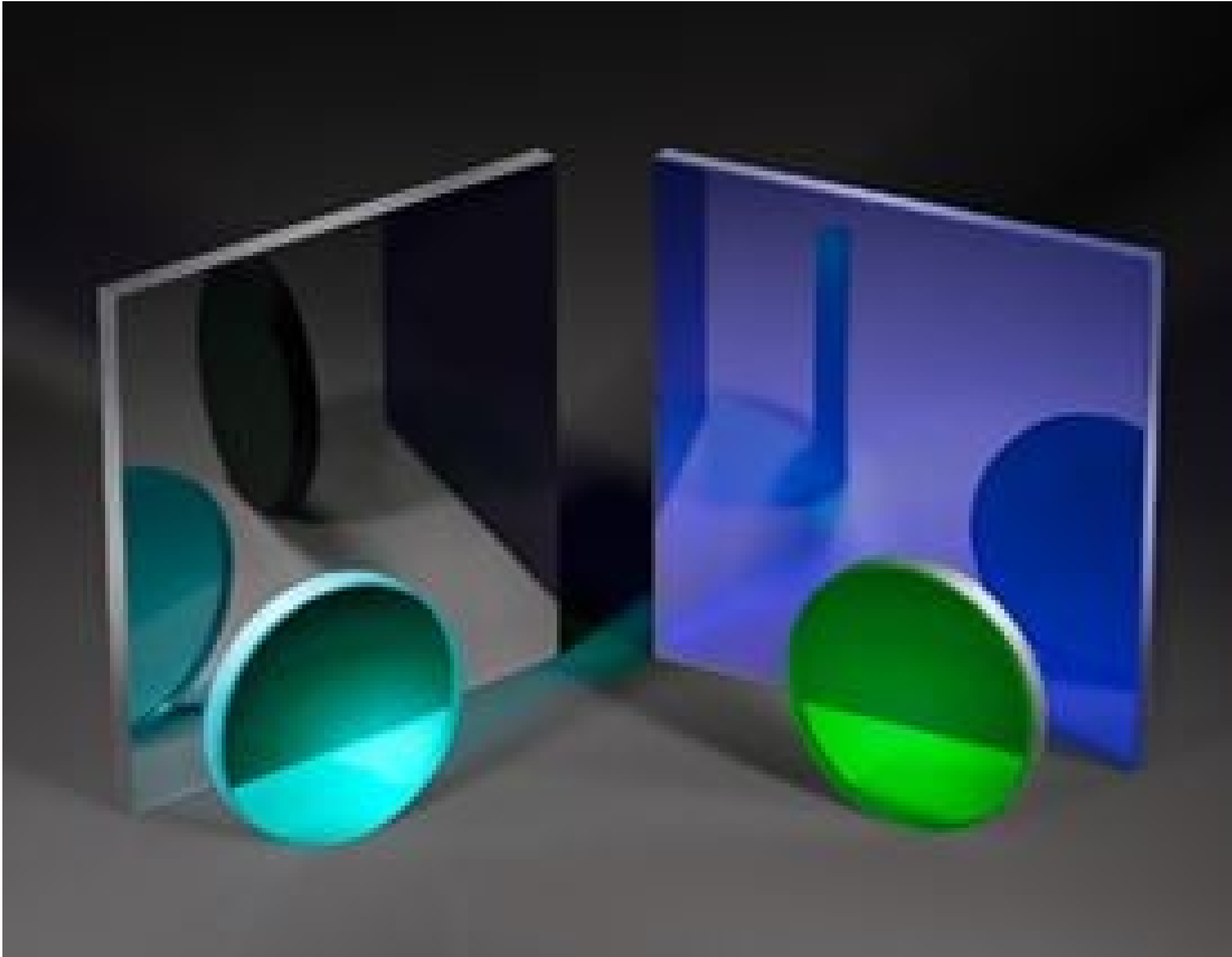

Stock **#18-777** 3-4 DAYS

[Additional Bandwidths](#)

- 1 + **€63,00**

ADD TO CART

Qty 1-10

€63,00

Qty 11+

€56,00

Volume Pricing

[Request Quote](#)

! Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.40

Center Wavelength CWL (nm): 370.00
Density (g/cm³): 2.36
Full Width-Half Max FWHM (nm): 100.00
Glass/Filter Number: Hoya B370
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Blue-Violet
Surface Quality: 60-40
Thickness (mm): 1.00
Thickness Tolerance (mm): ±0.1
Type: Bandpass Filter
Wavelength: UV-VIS
Parallelism (arcmin): ≤2
Dimensional Tolerance (mm): ±0.2

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View