 



# Hoya B370 (UVVIS) 50mm Dia., 2.5mm Thick, Colored Glass Bandpass Filter

See More by [Hoya](#)

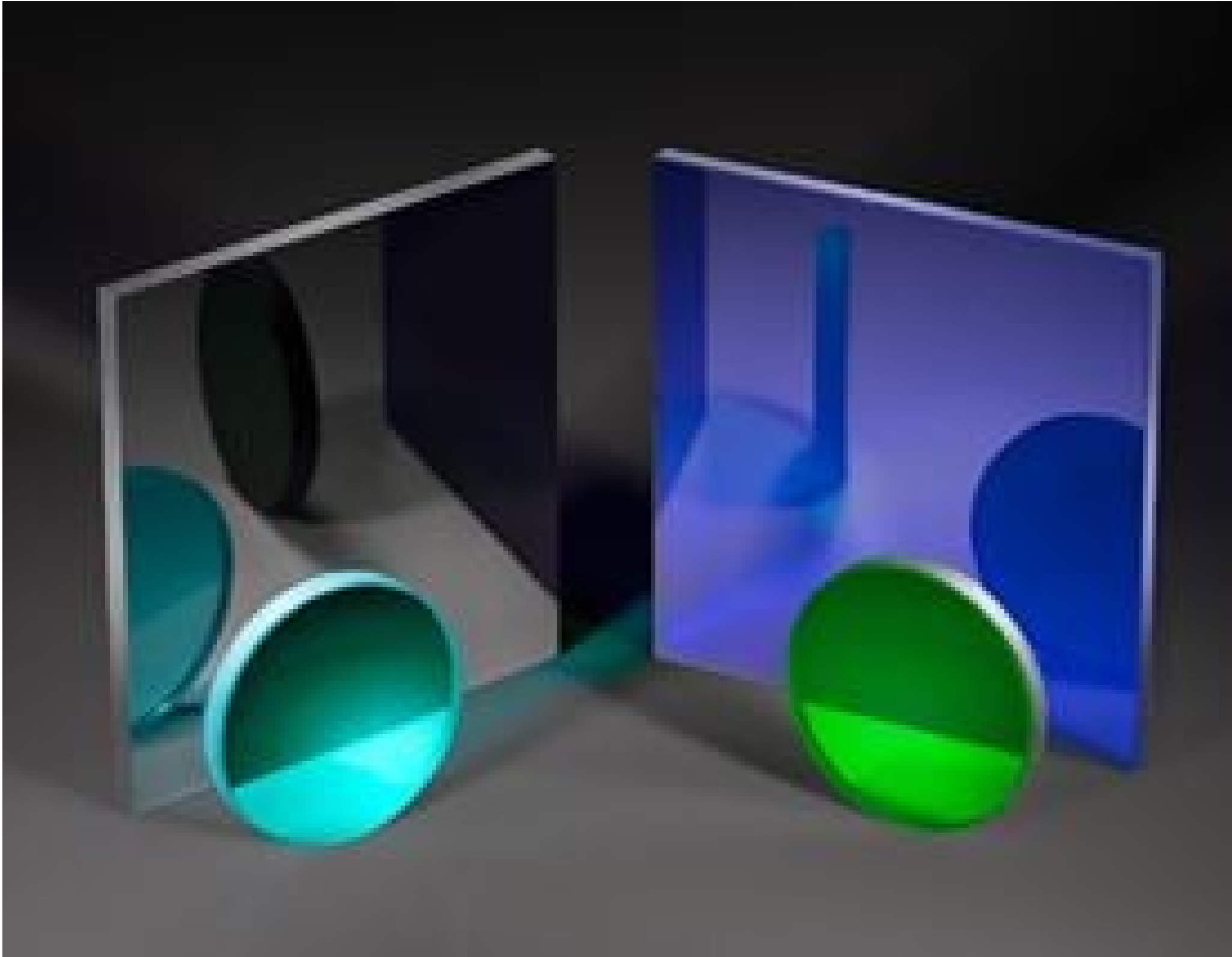

Stock **#18-779** 3-4 DAYS

[Additional Bandwidths](#)

- 1 +

€108,00

ADD TO CART

Qty 1-10

€108,00

Qty 11+

€96,00

Volume Pricing

[Request Quote](#)

**!** Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):  
50.00

|                                                      |
|------------------------------------------------------|
| Center Wavelength CWL (nm):<br>370.00                |
| Density (g/cm³):<br>2.36                             |
| Full Width-Half Max FWHM (nm):<br>100.00             |
| Glass/Filter Number:<br><a href="#">Hoya B370</a>    |
| Substrate: <input type="checkbox"/><br>Colored Glass |
| Coating:<br>Uncoated                                 |
| Color:<br>Blue-Violet                                |
| Surface Quality:<br>60-40                            |
| Thickness (mm):<br>2.50                              |
| Thickness Tolerance (mm):<br>±0.1                    |
| Type:<br>Bandpass Filter                             |
| Wavelength:<br>UV-VIS                                |
| Parallelism (arcmin):<br>≤2                          |
| Dimensional Tolerance (mm):<br>±0.2                  |

### Regulatory Compliance

|                                                     |
|-----------------------------------------------------|
| RoHS:<br><a href="#">Compliant</a>                  |
| Certificate of Conformance:<br><a href="#">View</a> |