 



Hoya U360 (UV) 12mm Dia., 1mm Thick, Colored Glass Bandpass Filter

See More by [Hoya](#)

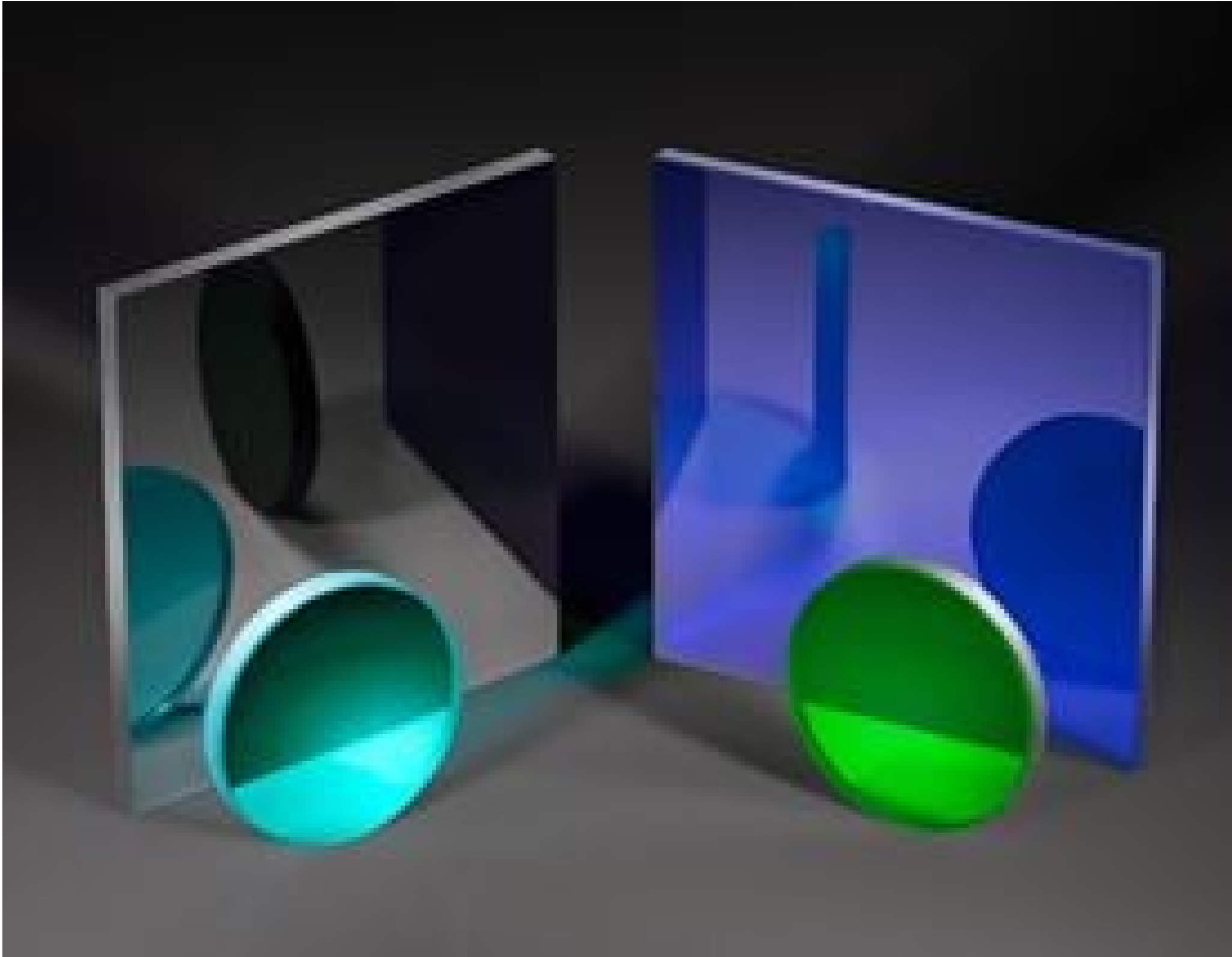

Stock **#18-771** 3-4 DAYS

[Additional Bandwidths](#)

- 1 + **€41,00**

ADD TO CART

Qty 1-10

€41,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.00

Center Wavelength CWL (nm): 360.00
Density (g/cm³): 2.74
Full Width-Half Max FWHM (nm): 45.00
Glass/Filter Number: Hoya U360
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Black
Surface Quality: 60-40
Thickness (mm): 1.00
Thickness Tolerance (mm): ±0.1
Type: Bandpass Filter
Wavelength: UV
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): ±0.2

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View