

## Iris Mount for 21mm Outer Diameter Irises



Iris Mount for 21mm Outer Diameter Irises, #54-862

Stock **#54-862** **4 In Stock**

⊖ 1 ⊕ €50<sup>00</sup>

**ADD TO CART**

### Volume Pricing

Qty 1-4	€50,50 each
Qty 5-9	€44,60 each
Qty 10-25	€41,30 each
Need More?	<a href="#">Request Quote</a>

ⓘ Prices shown are exclusive of VAT/local taxes

### Product Downloads

### Physical & Mechanical Properties

Compatible Iris Diameter (mm):  
21.0

Outer Diameter (mm):  
32.0

Thickness (mm):  
9.50

## Threading & Mounting

8-32  
**Mounting Threads:**  
 4-40  
**Set Screw Thread:**

## Regulatory Compliance

**RoHS 2015:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)


**Reach 235:**  
[Compliant](#)

## Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

## Technical Information

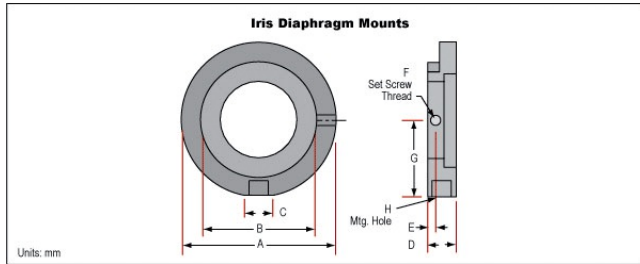

Iris Diameter	A	B	C	D	E	F	G	H	Stock No.
19.8	30.8	19.8	6.1	6.35	2.5	4-40	15.1	8-32	<a href="#">#53-918</a>
37.0	50.8	37.0	9.0	9.5	2.8	6-32	25.0	1/4-20	<a href="#">#53-919</a>
53.0	66.0	53.0	9.9	9.5	3.0	6-32	32.7	1/4-20	<a href="#">#53-920</a>
70.0	86.0	70.0	10.1	9.5	3.8	6-32	42.7	1/4-20	<a href="#">#53-921</a>
21.0	32.0	21.0	6.2	9.5	3.2	4-40	15.7	8-32	<a href="#">#54-862</a>
38.0	52.0	38.0	9.1	9.5	3.2	6-32	25.6	1/4-20	<a href="#">#54-863</a>
54.0	67.0	54.0	8.9	9.5	3.8	6-32	33.2	1/4-20	<a href="#">#54-864</a>
72.0	88.0	72.0	10.3	11.5	3.8	6-32	43.7	1/4-20	<a href="#">#54-865</a>