

Iris Mount for 54mm Outer Diameter Irises



Iris Mount for 70mm Outer Diameter Irises, #53-921



Stock **#54-864** **20+ In Stock**

⊖ 1 ⊕ €68⁰⁰

ADD TO CART

Volume Pricing

| | |
|------------|-------------------------------|
| Qty 1-4 | €68,00 each |
| Qty 5-9 | €60,30 each |
| Qty 10-25 | €55,80 each |
| Need More? | Request Quote |

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties

Compatible Iris Diameter (mm):

54.0

Outer Diameter (mm):

67.0

9.50 Thickness (mm):

Threading & Mounting

Mounting Threads:
 1/4-20
 Set Screw Thread:
 6-32

Regulatory Compliance


RoHS 2015:
[Compliant](#)
 Certificate of Conformance:
[View](#)
 Reach 235:
[Compliant](#)

Product Details

- Multiple Iris Diameter Options Available
- Durable Anodized Aluminum Construction
- Set Screw Included

Iris Diaphragm Mounts fit our most popular sizes of [Iris Diaphragms](#) and are constructed from durable black anodized aluminum. These mounts feature a variety of different English post mounting options, and each utilize an included set screw to ensure a secure fit.

Technical Information

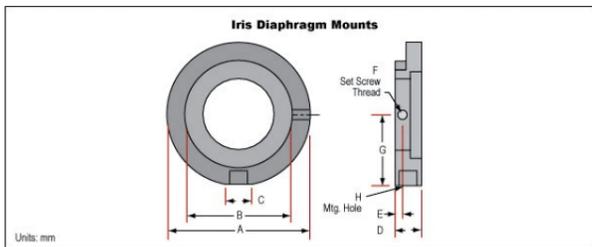

| Iris Diameter | A | B | C | D | E | F | G | H | Stock No. |
|---------------|------|------|------|------|-----|------|------|--------|-------------------------|
| 19.8 | 30.8 | 19.8 | 6.1 | 6.35 | 2.5 | 4-40 | 15.1 | 8-32 | #53-918 |
| 37.0 | 50.8 | 37.0 | 9.0 | 9.5 | 2.8 | 6-32 | 25.0 | 1/4-20 | #53-919 |
| 53.0 | 66.0 | 53.0 | 9.9 | 9.5 | 3.0 | 6-32 | 32.7 | 1/4-20 | #53-920 |
| 70.0 | 86.0 | 70.0 | 10.1 | 9.5 | 3.8 | 6-32 | 42.7 | 1/4-20 | #53-921 |
| 21.0 | 32.0 | 21.0 | 6.2 | 9.5 | 3.2 | 4-40 | 15.7 | 8-32 | #54-862 |
| 38.0 | 52.0 | 38.0 | 9.1 | 9.5 | 3.2 | 6-32 | 25.6 | 1/4-20 | #54-863 |
| 54.0 | 67.0 | 54.0 | 8.9 | 9.5 | 3.8 | 6-32 | 33.2 | 1/4-20 | #54-864 |
| 72.0 | 88.0 | 72.0 | 10.3 | 11.5 | 3.8 | 6-32 | 43.7 | 1/4-20 | #54-865 |

