


[All Products](#) / [Optics](#) / [Optical Filters](#) / [Longpass Filters](#) / [Linear Variable Edge Filters](#)

[See all 3 Products in Family](#)

Linear Variable Dichroic Filter

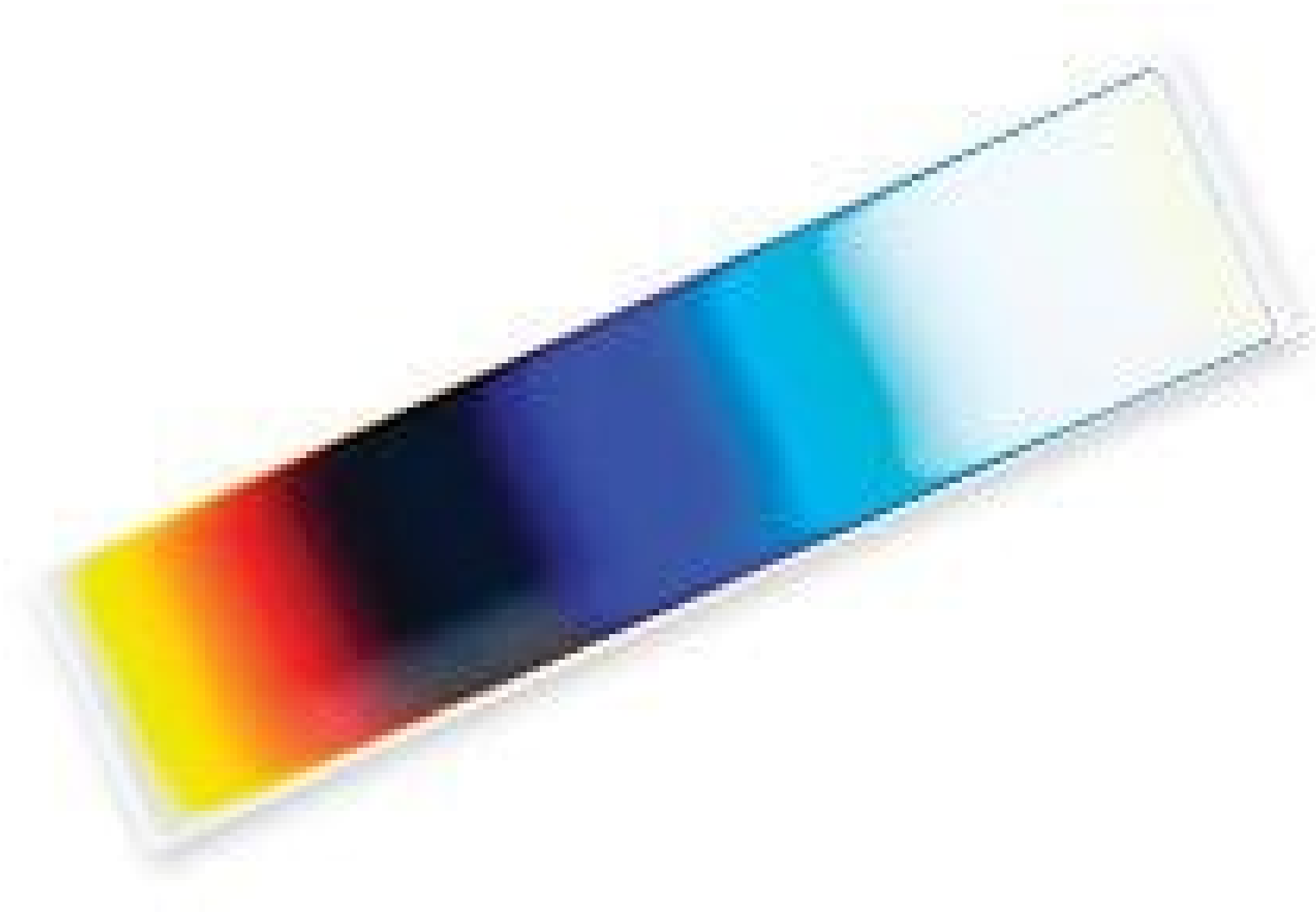

Stock **#88-364** 3-4 DAYS



1



€1.605,00

ADD TO CART

Qty 1-9

€1.605,00

Qty 10+

€1.440,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
60.0 x 15.0

Optical Density OD (Average):
≥2.0

Substrate: ☐
[Fused Silica](#) (Coming 7980)

Length (mm):

60.00
Coating: Variable
Optical Density Steps: Edge: 340 - 420nm, >3.0 from 300nm Edge: 420 - 500nm, >2.7 from 300nm Edge: 500 - 850nm, >2.0 from 390nm
Thickness (mm): 3.00
Transmission (%): >85
Type: Dichroic Filter
Width (mm): 15.00
Transmission Steps (%): Edge: 300 - 420nm, >85% over 200nm Edge: 420 - 500nm, >90% over 200nm Edge: 500 - 750nm, >90% over 200nm
Aperture (mm): 0.2 x 8.0
Wavelength Range (nm): 320 - 750

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View