


Linear Variable Longpass Filter

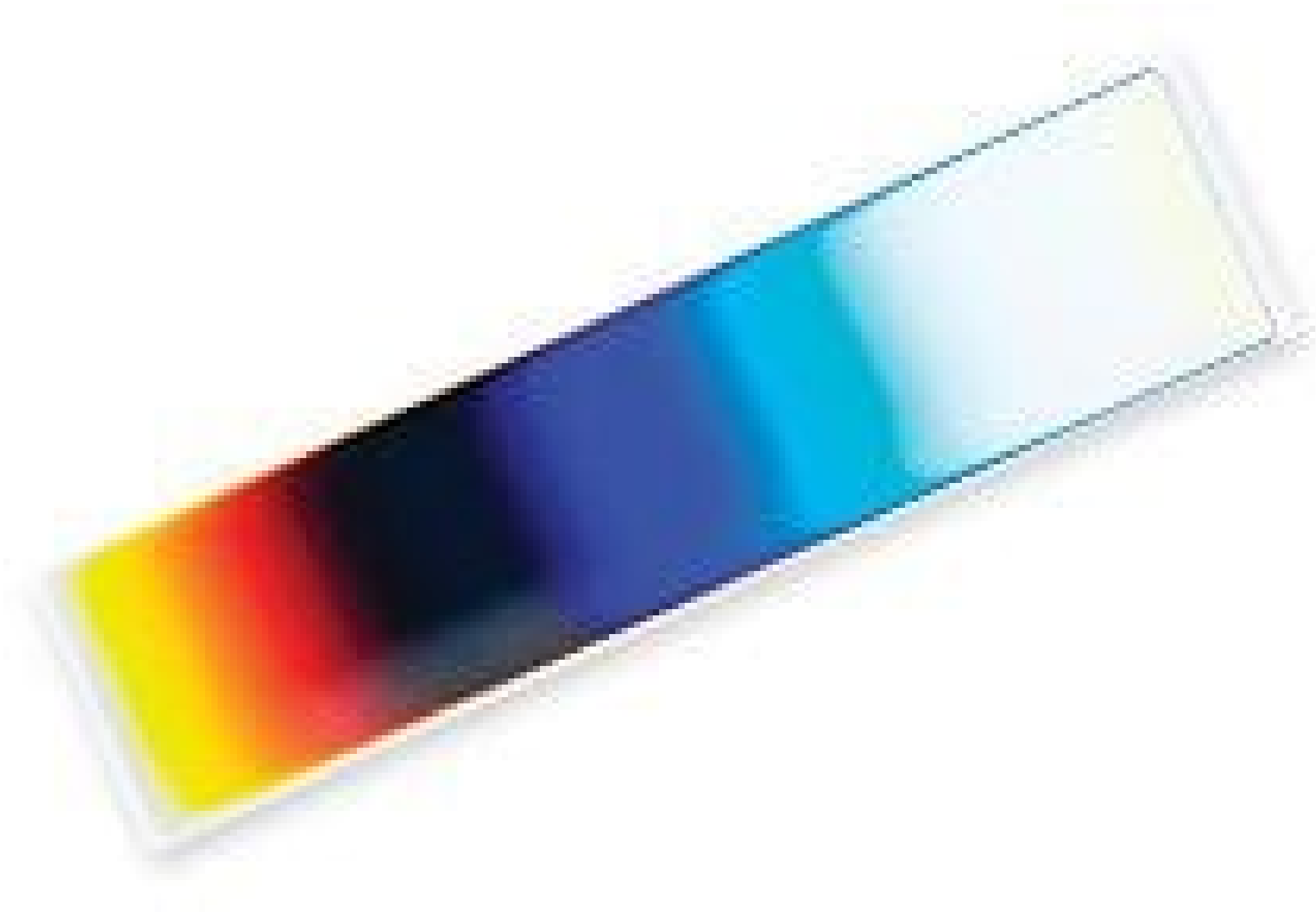

Stock **#88-363** 3-4 DAYS

- 1 + **€1.605,00**

ADD TO CART

Qty 1-9
€1.605,00
Qty 10+
€1.440,00
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):
60.0 x 15.0

Optical Density OD (Average):
≥3.1

Substrate: ☐
[Fused Silica](#) (Coming 7980)

Length (mm):

60.00
Coating: Variable
Optical Density Steps: Edge: 340 - 420nm, >3.3 from 300nm Edge: 420 - 500nm, >3.3 from 300nm Edge: 500 - 850nm, >3.1 from 350nm
Thickness (mm): 3.00
Transmission (%): >92
Type: Longpass Filter
Width (mm): 15.00
Transmission Steps (%): Edge: 300 - 420nm, >92% over 40nm Edge: 420 - 700nm, >92% over 40nm Edge: 500 - 850nm, >92% over 40nm
Aperture (mm): 0.2 x 8.0
Wavelength Range (nm): 300 - 850

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View