


Medium Thick Base Single Movement

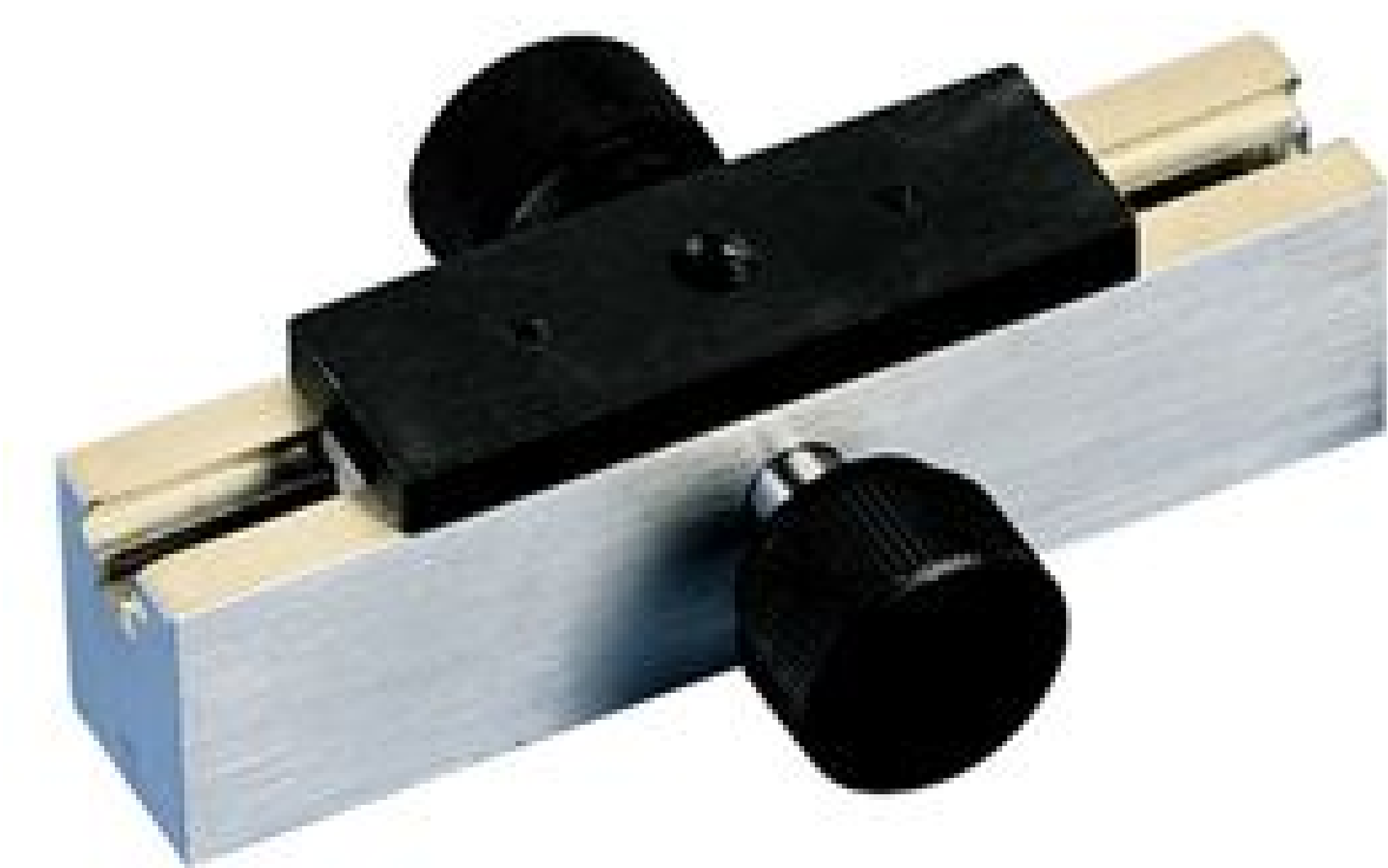

#03-681

Stock **#03-681** 6 In Stock

-

1

+

€232⁷⁸

ADD TO CART

Volume Pricing	
Qty 1-9	€232,78 each
Qty 10+	€205,49 each
Need More?	Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

SPECIFICATIONS

General

English

Type:

Note:

Not Lockable

Physical & Mechanical Properties

Linear (X)	Type of Movement:
Dovetail	Guide System:
20 x 100	Stage Size (mm):
40 (±20)	Travel (mm):
3.5 Horizontal, 2.1 Vertical	Load Capacity (kg):
50	Straight Line Accuracy (µm):
15	Travel Per Knob Rotation (mm):
422	Weight (g):
20 x 60	Table Size (mm):

Hardware & Interface Connectivity

Rack and Pinion	Type of Drive:
-----------------	----------------

Threading & Mounting

Stage: (1) 1/4-20 Base: (3) 1/4-20	Mounting Threads:
---------------------------------------	-------------------

Regulatory Compliance

Exempt	RoHS 2015:
View	Certificate of Conformance:
Contains SVHC(s)	Reach 235:

PRODUCT DETAILS

- Multiple Configurations Available
- High Load Capacity
- Ideal for Applications Requiring Long Travel
- Additional [Rack and Pinion Stages](#) Available

Basic Rack and Pinion Stages are ideal for applications requiring high load capacity or long travel. These stages feature horizontal load capacities of 3.5kg and vertical load capacities of 2.1kg. Each stage offers stage and base mounting holes and features steel construction with brass movement. Basic Rack and Pinion Stages are available in multiple configurations with varying stage sizes. These stages have a Dovetail guide system.

TECHNICAL INFORMATION

#03-681 Thick Base Single Axis

