

[See all 14 Products in Family](#)

Olympus PLN 40X Objective

See More by [Olympus](#)



Olympus Plan Achromatic Objectives



Stock #86-815 **4 In Stock**

- 1 + €755.⁰⁰

ADD TO CART

| Volume Pricing | |
|----------------|-------------------------------|
| Qty 1+ | €755,00 each |
| Need More? | Request Quote |

ⓘ Prices shown are exclusive of VAT/local taxes

Product Downloads

General

Model Number:
PLN40X

Compatible Tube Lens Focal Length (mm):
Focal Length: 180mm

Type:
Microscope Objective

Infinity Corrected **Style:**

Olympus **Manufacturer:**

Physical & Mechanical Properties

0.55 **Field of View (mm):**

44.30 **Length excluding Threads (mm):**

24 **Maximum Diameter (mm):**

110.6 **Weight (g):**

Optical Properties

0.17 **Compatible Cover Glass Thickness (mm):**

4.50 **Focal Length FL (mm):**

40X **Magnification:**

0.65 **Numerical Aperture NA:**

0.52 **Resolving Power (μm):**

0.65 **Depth of Field (μm):**

0.6 **Working Distance (mm):**

22 **Field Number (mm):**

45 **Parfocal Length (mm):**

N/A **Immersion Liquid:**

1041 **Depth of Focus (μm):**

5.85 **Entrance Pupil Diameter (mm):**

Threading & Mounting

RMS / 20.32mm x 36 TPI **Mounting Threads:**

Regulatory Compliance


[View](#) **Certificate of Conformance:**

Product Details

- Ideal for Brightfield, Darkfield, or Fluorescence Microscopy
- Excellent Price-to-Performance Ratio
- Suitable for Introductory and Advanced Optical Microscopy Applications
- Additional [Olympus Infinity Corrected Objectives](#) Available

Olympus Plan Achromatic Objectives are designed for clinical laboratory or examination applications. When using brightfield observation in a transmitted illumination system, Olympus Plan Achromatic Objectives provide excellent field flatness of up to F.N.22.

Technical Information

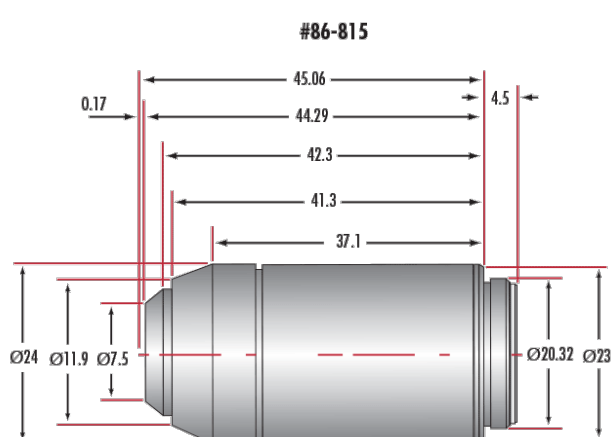

Using Olympus Objectives with C-Mount Cameras



| | Stock # | A | B | C | D | E | F | G |
|----------|------------------------|------|-----|-----|------|------|------|-----|
| PLN 2X | 16-879 | 39.1 | 3.4 | 0.0 | 16.8 | 16.8 | 24.0 | 4.5 |
| PLN 4X | 86-812 | 26.4 | 4.4 | 0.0 | 15.8 | 15.8 | 24.0 | 4.5 |
| PLN 10X | 86-813 | 34.3 | 4.1 | 1.6 | 10.5 | 16.0 | 24.0 | 4.5 |
| PLN 20X | 86-814 | 43.7 | 4.2 | 2.4 | 6.1 | 15.6 | 24.0 | 4.8 |
| PLN 40X | 86-815 | 44.3 | 4.2 | 3.0 | 7.5 | 15.6 | 24.0 | 4.5 |
| PLN 100X | 86-816 | 44.7 | 4.2 | 2.5 | 6.6 | 15.6 | 24.0 | 4.5 |

