


[All Products](#) / [Cameras](#) / [USB Cameras](#) / [Pixelink® USB 3.0 Cameras](#)

[See all 74 Products in Family](#)

Pixelink PL-D752CU-T, 1/1.2" 2.3MP, C-Mount USB 3.0 Color Camera

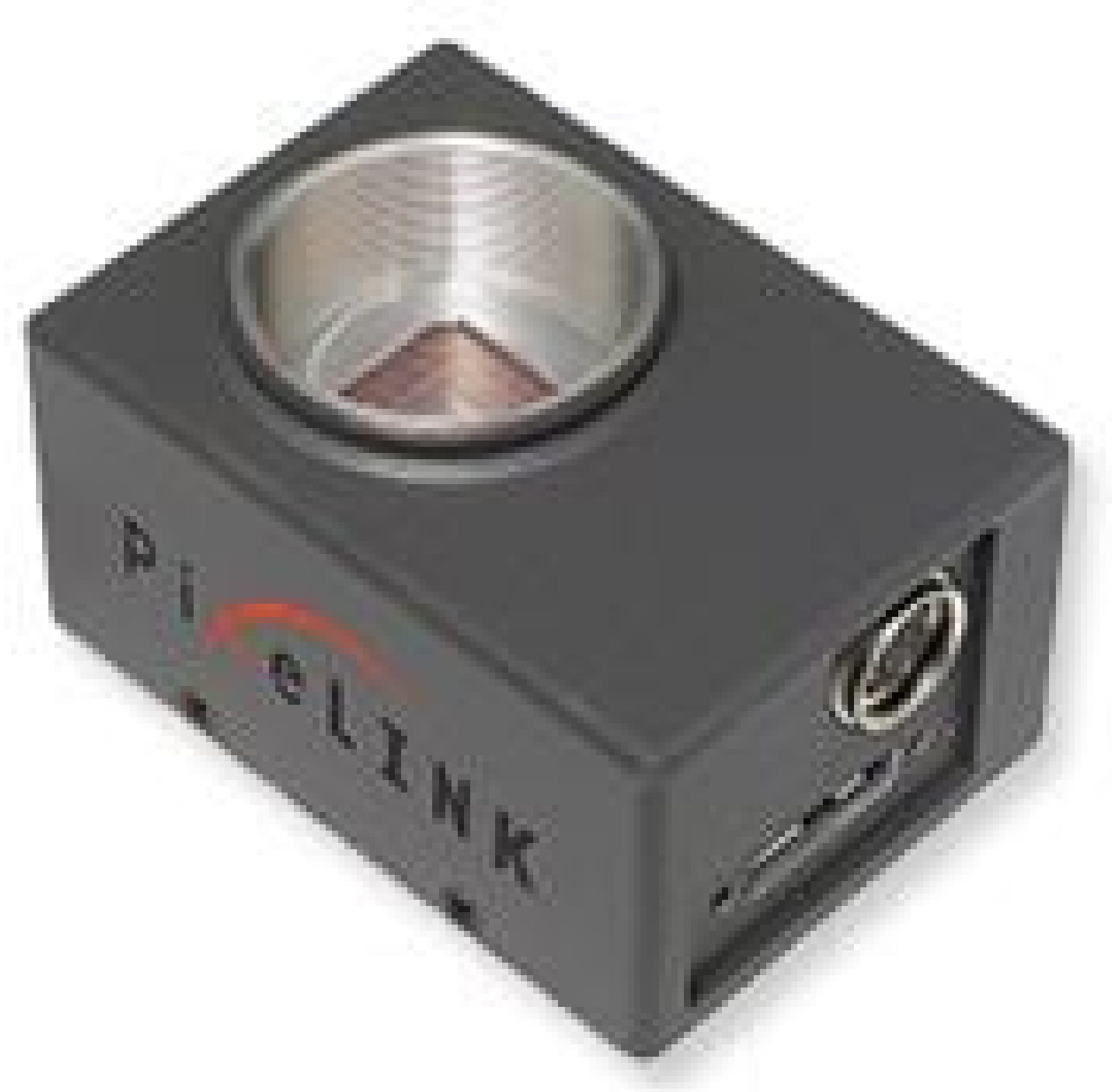

Pixelink® USB 3.0 Cameras (Full Housing)



Stock **#33-347** [CONTACT US](#)

[Similar Cameras](#)



1



€1.495,00

ADD TO CART

Qty 1+

€1.495,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Video Output:
USB 3.0

Type:
Color Camera

Manufacturer: Pixelink
Mounting Threads: ¼-20 with Tripod Mount Adapter #89-408
Image Buffer: Not Specified
Camera Family: PL-D
Model Number: PL-D752CU-T
Imaging Sensor: Sony IMX174
Type of Sensor: Progressive Scan CMOS
Type of Shutter: Global
Camera Sensor Format: 1/1.2"
Resolution (MegaPixels): 2.30
Pixels (H x V): 1,920 x 1,200
Pixel Size, H x V (µm): 5.86 x 5.86
Sensing Area, H x V (mm): 11.25 x 7.03
Frame Rate (fps): 129.00
Pixel Depth: 8/12 bit
Exposure Time: 19µs - 120s
Connector: USB 3.0, Micro-B
Power Supply: Power over USB
Power Consumption (W): Not Specified
GPIOs: 1 opto-isolated trigger input, 1 opto-isolated output, 2 non-isolated outputs, 1 non-isolated input
Synchronization: Hardware Trigger (GPIO) or Software Trigger
Dimensions (mm): 55 x 38.5 x 27 (excludes connectors and lens mount)
Weight (g): 89
Mount: C-Mount
Housing: Full
Interface Port Orientation: Side Panel
Dynamic Range (dB): 70
Operating Temperature (°C): 0 to +50
Storage Temperature (°C): -45 to +85
GPIO Connector Type: 8-pin Hirose (HR25)
Machine Vision Standard: USB3 Vision v1.0
Operating System: Software Driver: Windows 32 and 64 bit

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View

