 



# Hoya RT830 (IR) 50.8mm Square, Colored Glass Bandpass Filter

See More by [Hoya](#)

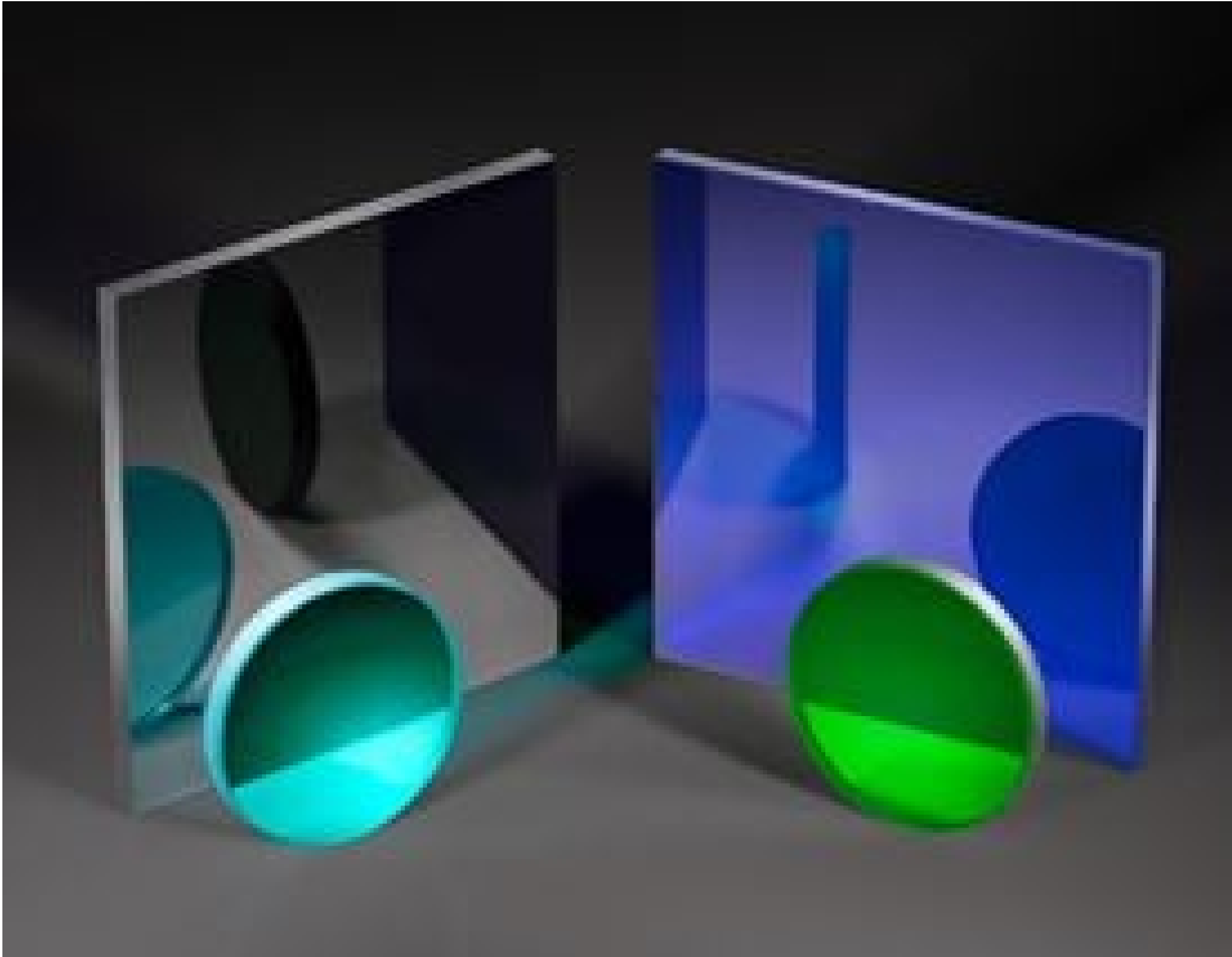

Stock **#46-444** 3-4 DAYS

- 1 +

€108,00

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| €108,00                       |
| Qty 11+                       |
| €96,00                        |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Dimensions (mm):  
50.8 x 50.8

Center Wavelength CWL (nm):

|                                                      |
|------------------------------------------------------|
| 830.00                                               |
| Density (g/cm³):<br>2.75                             |
| Full Width-Half Max FWHM (nm):<br>260.00             |
| Glass/Filter Number:<br><a href="#">Hoya RT830</a>   |
| Substrate: <input type="checkbox"/><br>Colored Glass |
| Length (mm):<br>50.80                                |
| Coating:<br>Uncoated                                 |
| Color:<br>Black                                      |
| Surface Quality:<br>60-40                            |
| Thickness (mm):<br>2.50                              |
| Thickness Tolerance (mm):<br>±0.2                    |
| Type:<br>Bandpass Filter                             |
| Wavelength:<br>IR                                    |
| Width (mm):<br>50.80                                 |
| Parallelism (arcmin):<br>≤2                          |
| Dimensional Tolerance (mm):<br>+0/-0.25              |

Regulatory Compliance

|                                                     |
|-----------------------------------------------------|
| RoHS 2015:<br><a href="#">Exempt</a>                |
| Reach 224:<br><a href="#">Compliant</a>             |
| Certificate of Conformance:<br><a href="#">View</a> |