 



In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union

SUBMIT

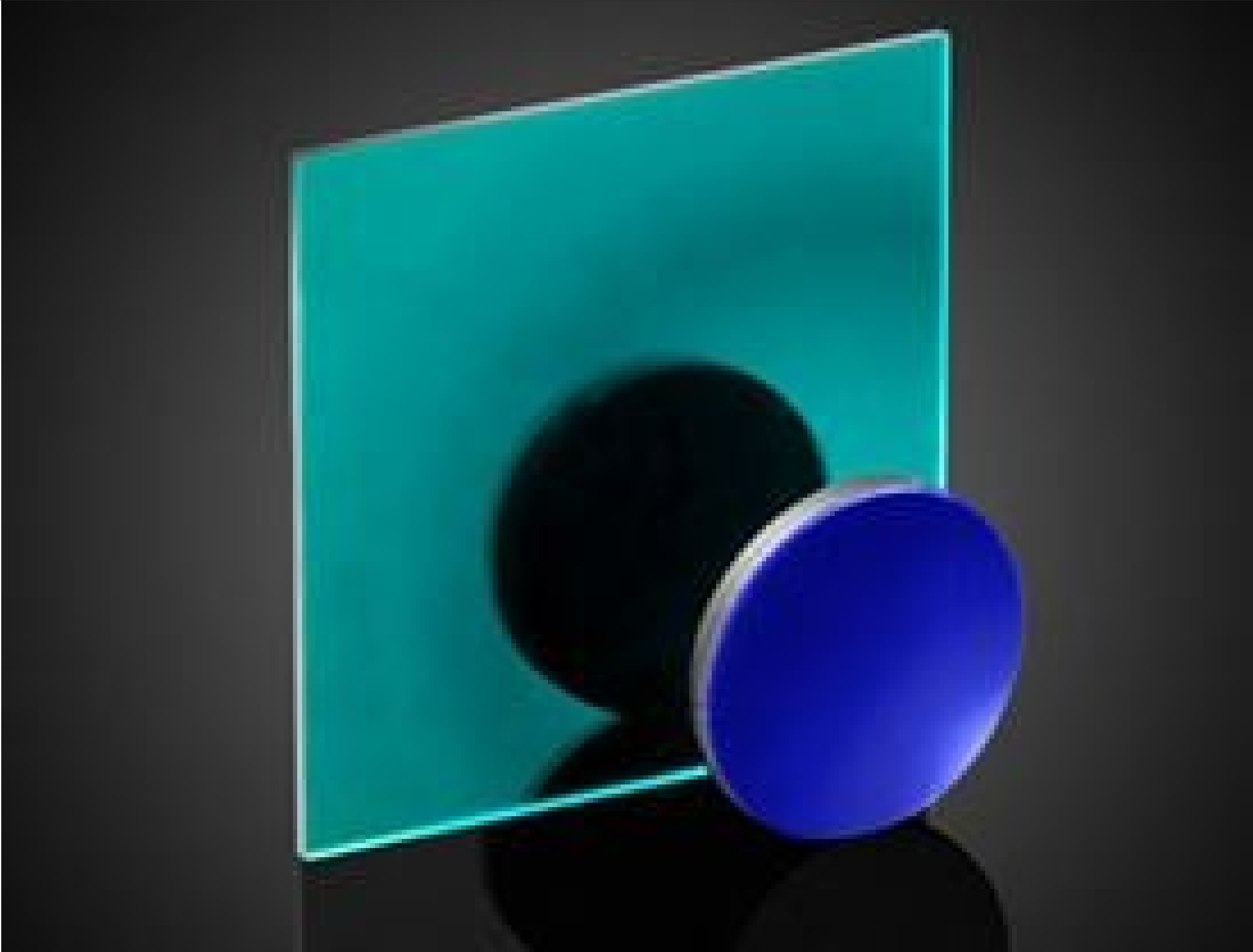

Stock #14-443 3-4 DAYS



1



€88,00

ADD TO CART

Qty 1-10

€88,00

Qty 11+

€78,00

Volume Pricing

[Request Quote](#)

 Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Dimensions (mm):

50.0 x 50.0

Center Wavelength CWL (nm):

525.00

Density (g/cm³): 2.87
Glass/Filter Number: SCHOTT VG9
Length (mm): 50.00
Coating: Uncoated
Color: Green
Index of Refraction n_d: 1.55
Surface Quality: 60-40
Transformation Temperature (°C): 462
Thickness (mm): 2.00 ±0.2
Type: Bandpass Filter
Wavelength: VIS
Width (mm): 50.00
Bevel: Protective as needed

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View