 



Hoya U360 (UV) 12mm Dia., Colored Glass Bandpass Filter

See More by [Hoya](#)

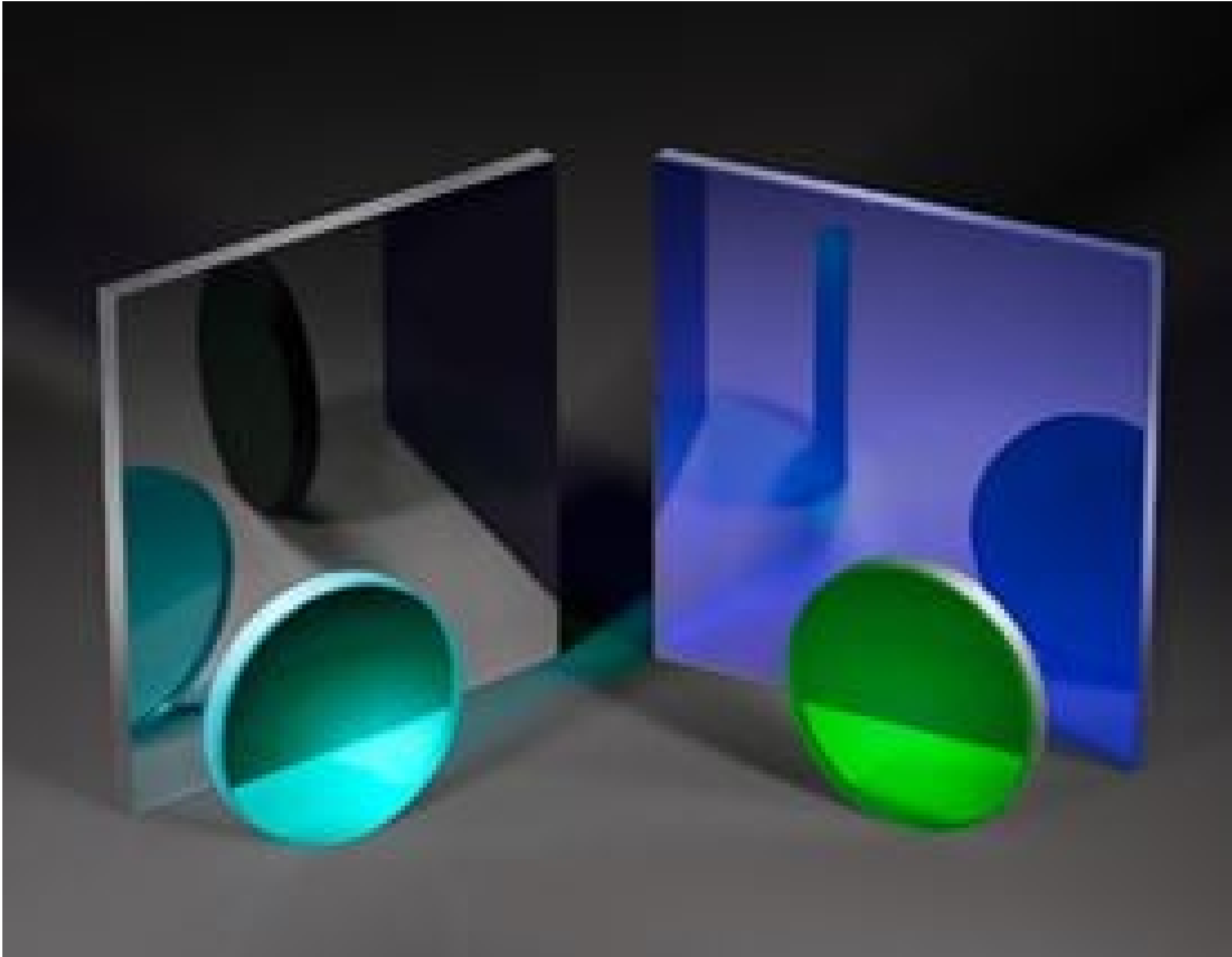

Stock **#46-081** 3-4 DAYS

[Additional Bandwidths](#)

- 1 + **€41,00**

ADD TO CART

Qty 1-10

€41,00

Qty 11+

€37,00

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
12.00

Center Wavelength CWL (nm): 360.00
Density (g/cm³): 2.74
Full Width-Half Max FWHM (nm): 45.00
Glass/Filter Number: Hoya U360
Substrate: ☐ Colored Glass
Coating: Uncoated
Color: Black
Surface Quality: 80-50
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.2
Type: Bandpass Filter
Wavelength: UV
Parallelism (arcmin): ≤1
Dimensional Tolerance (mm): +0/-0.25

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Compliant
Certificate of Conformance: View