


Variable Frequency Target 5-120 lp/mm

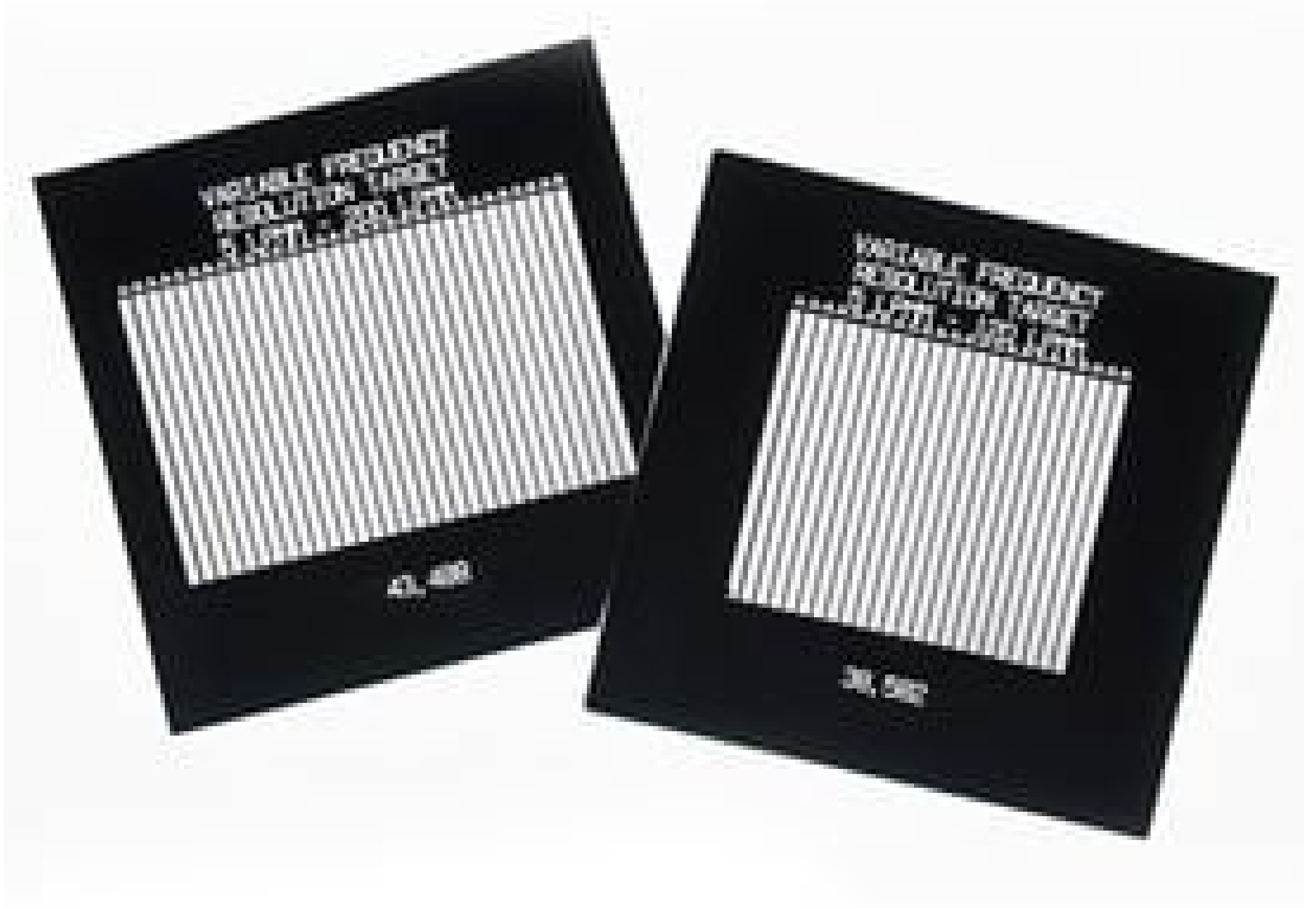

Stock #38-582 CLEARANCE 5 In Stock

€665^{.00}

ADD TO CART

Volume Pricing

Qty 1+	€665,00 each
Need More?	Request Quote

Prices shown are exclusive of VAT/local taxes

Product Downloads

Physical & Mechanical Properties

25.4 x 29.85 **Pattern Size (mm):**

2 x 2 **Dimensions (inches):**

1.50 **Thickness (mm):**

Beveled **Edges:**

Flatness (mm):

Optical Properties

Vacuum deposited durable chromium **Coating:**

Float Glass **Substrate:**

≥3.0 **Optical Density OD (Average):**

40-10 **Surface Quality:**

Regulatory Compliance

[Compliant](#) **RoHS 2015:**

[View](#) **Certificate of Conformance:**

[Compliant](#) **Reach 240:**

Product Details

- 5 lp/mm to 120 lp/mm or 5 lp/mm to 200 lp/mm
- 1mm Wide Step Size
- 5 lp/mm Step Increments
- Used to Calibrate Video Systems
- Inspect Unknown Resolutions

Variable frequency targets are excellent for evaluating resolution, field distortion, and parfocal stability.